


## Connection cable

VDOAF040SCS00,3T04STGF040SCS

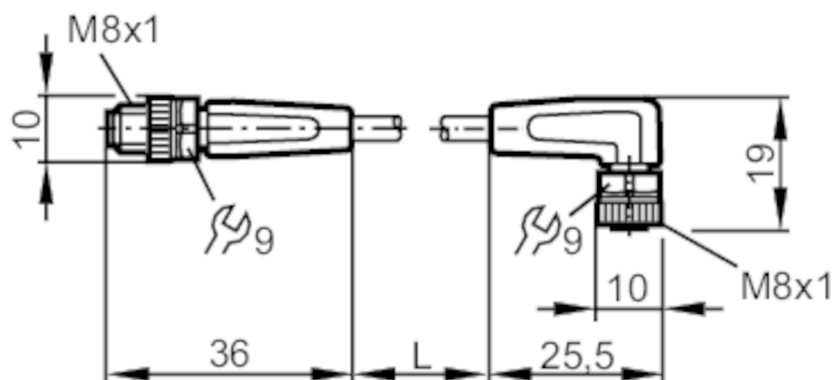

## Application

|                    |                                                                                |
|--------------------|--------------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Application        | welding applications                                                           |
| Free from silicone | yes                                                                            |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 50 AC / < 60 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

## Operating conditions

|                              |      |                             |
|------------------------------|------|-----------------------------|
| Ambient temperature          | [°C] | -25...90                    |
| Ambient temperature (moving) | [°C] | -25...90                    |
| Protection                   |      | IP 65; IP 67; IP 68; IP 69K |

## Tests / approvals

|             |    |       |
|-------------|----|-------|
| UL approval | Ta | 75 °C |
|-------------|----|-------|

## Mechanical data

|                        |      |                                   |
|------------------------|------|-----------------------------------|
| Weight                 | [g]  | 27.9                              |
| Dimensions             | [mm] | 10 x 10 x 36                      |
| Materials              |      | housing: TPU orange; Sealing: FKM |
| Material nut           |      | brass, anti-spatter               |
| Drag chain suitability |      | yes                               |



## Connection cable

VDOAF040SCS00,3T04STGF040SCS

|                        |                                 |                                                                                                |
|------------------------|---------------------------------|------------------------------------------------------------------------------------------------|
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                                       |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup> |
|                        | bending cycles                  | > 5 Mio.                                                                                       |
|                        | torsional strain                | ± 180 °/m                                                                                      |

### Remarks

|               |                       |
|---------------|-----------------------|
| Remarks       | without label holders |
| Pack quantity | 1 pcs.                |

### Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, grey, Ø 4.5 mm; not irradiated (can be recycled); resistant to welding sparks; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

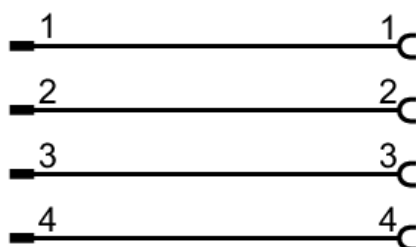

### Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

