


Connection cable for the connection of safety light curtains

ADAPTER CABLE TRANSM.HIGH RANG

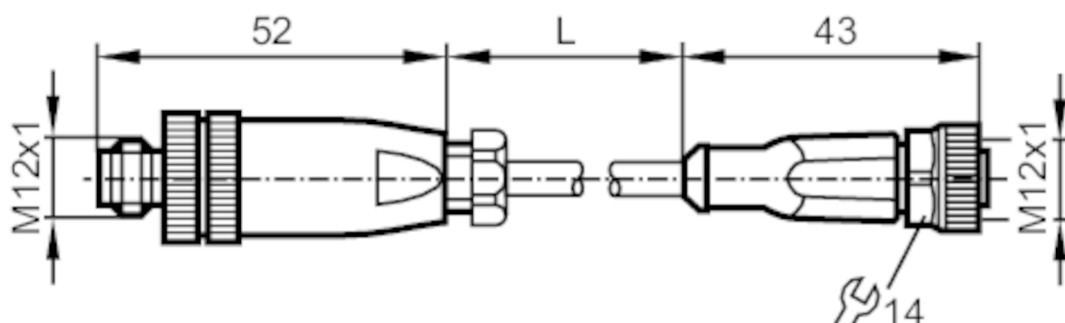

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Design	Для підключення світлових завіс безпеки / багатопромених бар'єрів безпеки з OSSD, for transmitters
Application	configured for "long range"
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 36 DC
Protection class	II
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Protection	IP 67
Mechanical data	
Weight [g]	44.7
Materials	TPU orange; PA
Moulded-body material	TPU / PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.



Connection cable for the connection of safety light curtains


ADAPTER CABLE TRANSM.HIGH RANG

Electrical connection


Cable: 0.1 m, PUR, Halogen-free, black, Ø 4.9 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PA, orange; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

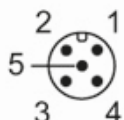

Connection

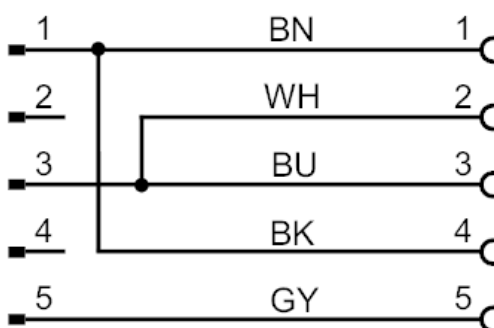

Core colours :
 BK = black
 BN = brown
 BU = blue
 GY = grey
 WH = white

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU / PA, orange; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

