




Inductive sensor

IFK3004BBPKG/M/V4A/US-104-DPS

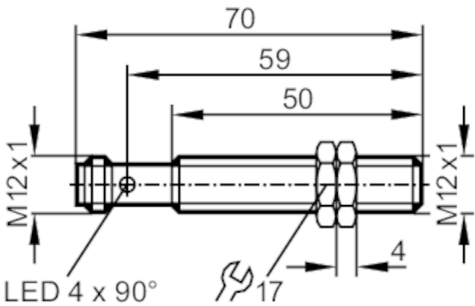

Product characteristics		
Electrical design		PNP
Output function		normally open
Sensing range	[mm]	4
Housing		threaded type
Dimensions	[mm]	M12 x 1 / L = 70
Application		
Special feature		Gold-plated contacts; Increased sensing range
Application		regular cleaning processes
Electrical data		
Operating voltage	[V]	10...36 DC
Current consumption	[mA]	< 10
Protection class		II
Reverse polarity protection		yes
Outputs		
Electrical design		PNP
Output function		normally open
Max. voltage drop switching output DC	[V]	2.5
Permanent current rating of switching output DC	[mA]	100
Switching frequency DC	[Hz]	700
Short-circuit protection		yes
Type of short-circuit protection		pulsed
Overload protection		yes
Detection zone		
Sensing range	[mm]	4
Operating distance	[mm]	0...3.25
Increased sensing range		yes
Accuracy / deviations		
Correction factor		steel: 1 / stainless steel: 0.7 / brass: 0.5 / aluminium: 0.5 / copper: 0.4

IFT216



Inductive sensor

IFK3004BBPKG/M/V4A/US-104-DPS

Hysteresis	[X01]	1...15
------------	-------	--------

Operating conditions

Ambient temperature	[°C]	0...100
---------------------	------	---------

Protection		IP 68; IP 69K
------------	--	---------------

Tests / approvals

EMC	EN 61000-4-2 ESD	4 kV CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-5 Surge	0,5 kV
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B

MTTF	[ANN]	1134
------	-------	------

UL approval	Ta	0...40 °C
	Enclosure type	Type 1
	подача напруги	Limited Voltage/Current
	File number UL	E174191

Mechanical data

Weight	[g]	30
--------	-----	----

Housing		threaded type
---------	--	---------------

Mounting		flush mountable
----------	--	-----------------

Dimensions	[mm]	M12 x 1 / L = 70
------------	------	------------------

Thread designation		M12 x 1
--------------------	--	---------

Materials		stainless steel (316L/1.4404); sensing face: PEEK
-----------	--	---

Displays / operating elements

Display	switching status	4 x 90° LED, yellow
---------	------------------	---------------------

Аксессуары

Items supplied		lock nuts: 2
----------------	--	--------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12; coding: A; Contacts: gold-plated



IFT216



Inductive sensor

IFK3004BBPKG/M/V4A/US-104-DPS

Connection

