


MK501A



T-slot cylinder sensor

MKT3028BBPKG/G/0,3M/ZH/US/3D

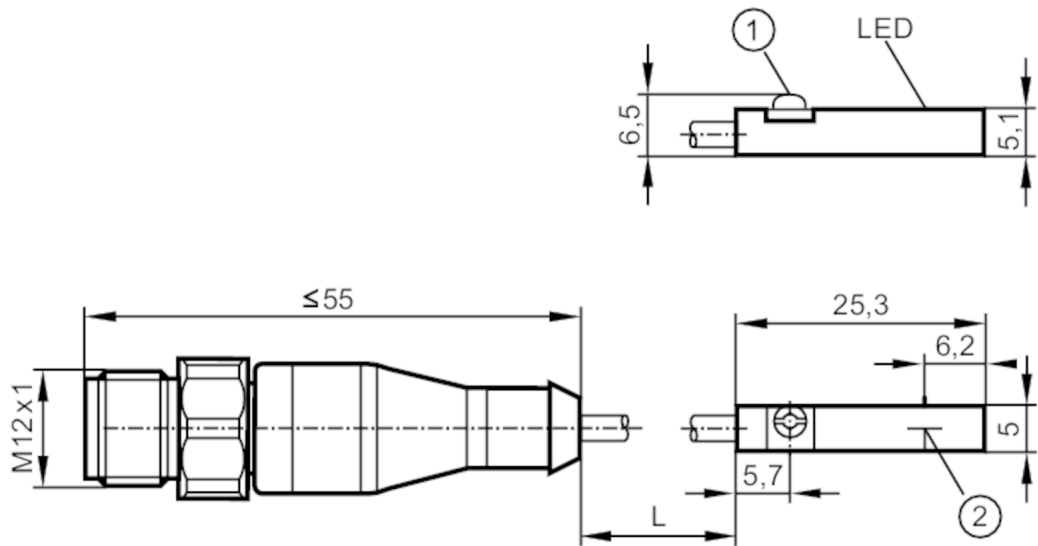

- 1 fastening clamp
2 Sensing face



Product characteristics

Electrical design	PNP
Output function	normally open
Dimensions [mm]	25 x 5 x 6.5

Electrical data

Operating voltage [V]	10...30 DC
Current consumption [mA]	< 10
Protection class	III
Reverse polarity protection	yes
Max. power-on delay time [ms]	30

Outputs

Electrical design	PNP
Output function	normally open
Max. voltage drop switching output DC [V]	2.5
Permanent current rating of switching output DC [mA]	100
Switching frequency DC [Hz]	10000
Short-circuit protection	yes
Overload protection	yes

Detection zone

Response sensitivity [mT]	2.8
Travel speed [m/s]	> 10

Accuracy / deviations

Hysteresis [mm]	< 1.5
-----------------	-------

MK501A



T-slot cylinder sensor

MKT3028BBPKG/G/0,3M/ZH/US/3D

Repeatability	[mm]	< 0.2
---------------	------	-------

Operating conditions

Ambient temperature	[°C]	-25...60
---------------------	------	----------

Protection	IP 65; IP 67
------------	--------------

Tests / approvals

ATEX marking	II 3D Ex tc IIIC T125°C Dc X
--------------	------------------------------

EMC	EN 61000-4-2 ESD	- CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B

MTTF	[ANN]	3694
------	-------	------

Mechanical data

Weight	[g]	52.4
--------	-----	------

Mounting	flush mountable
----------	-----------------

Type of mounting	fastening clamp with combined slot / hexagon socket, width across flats 1.5
------------------	---

Cylinder type	T-slot cylinders; (adapters allow mounting to different cylinder types)
---------------	---

Dimensions	[mm]	25 x 5 x 6.5
------------	------	--------------

Materials	PA; stainless steel
-----------	---------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Аксессуары

Items supplied	rubber placeholder: 1
	Cable clip: 1
	Protective cover: 1 x T-Nut, E12259

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Cable: 0.3 m, PUR

Connector: 1 x M12; coding: A; Locking: Hexagon nut, rotatable, stainless steel



MK501A



T-slot cylinder sensor

MKT3028BBPKG/G/0,3M/ZH/US/3D

Connection

