


MK5215



T-slot cylinder sensor

MKT3028BBPKG/G/WFI/0,3M/ZH/ASR

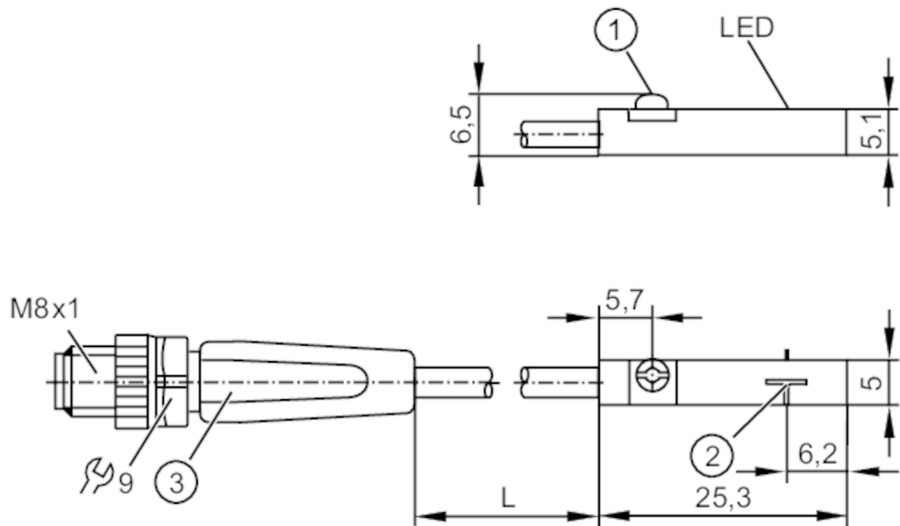

- 1 fastening clamp
- 2 Sensing face
- 3 illustration (example)



Product characteristics		
Electrical design		PNP
Output function		normally open
Dimensions	[mm]	25 x 5 x 6.5
Application		
Special feature		Magnetic-field immune
Operating principle		suppression of extraneous fields
Application		welding applications
Magnetic-field immune		yes
Max. magnetic field immunity	[mT]	200
Electrical data		
Operating voltage	[V]	10...30 DC
Current consumption	[mA]	< 10
Protection class		III
Reverse polarity protection		yes
Max. power-on delay time	[ms]	300
Outputs		
Electrical design		PNP
Output function		normally open
Max. voltage drop switching output DC	[V]	2.5
Permanent current rating of switching output DC	[mA]	100
Switching frequency DC	[Hz]	9
Short-circuit protection		yes

MK5215



T-slot cylinder sensor

MKT3028BBPKG/G/WFI/0,3M/ZH/ASR

Overload protection		yes	
Detection zone			
Response sensitivity		[mT]	2.8
Travel speed		[m/s]	< 0.25
Accuracy / deviations			
Hysteresis		[mm]	< 1.5
Repeatability		[mm]	< 0.2
Operating conditions			
Ambient temperature		[°C]	-25...85
Protection		IP 65; IP 67	
Tests / approvals			
EMC	EN 61000-4-2 ESD		- CD / 8 kV AD
	EN 61000-4-3 HF radiated		10 V/m
	EN 61000-4-4 Burst		2 kV
	EN 61000-4-6 HF conducted		10 V
	EN 55011		class B
Vibration resistance	EN 60068-2-6 Fc		(10...55 Hz) / 1 mm amplitude, oscillation period 5 min., 30 min. per axis at resonance or 55 Hz
Shock resistance	EN 60068-2-27 Ea		30 g 6 shocks / 11 ms half-sine (x, y, z)
UL approval	UL Approval no.		C003
Mechanical data			
Weight		[g]	17
Mounting		flush mountable	
Type of mounting		fastening clamp with combined slot / hexagon socket, width across flats 1.5	
Cylinder type		T-slot cylinders	
Dimensions		[mm]	25 x 5 x 6.5
Materials		housing: PA; fastening clamp: stainless steel; knurled nut: PTFE coated; protective tube: PTFE coated	
Displays / operating elements			
Display		switching status	1 x LED, yellow
Аксессуары			
Items supplied		rubber placeholder: 1	
		Cable clip: 1	
Remarks			
Remarks		operating voltage "supply class 2" according to cULus	
Pack quantity		1 pcs.	

MK5215



 
T-slot cylinder sensor

MKT3028BBPKG/G/WFI/0,3M/ZH/ASR

Electrical connection - plug

Cable: 0.3 m, PUR; protective tube

Connector: 1 x M8; coding: A; Locking: knurled nut, rotatable



Connection

