




T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

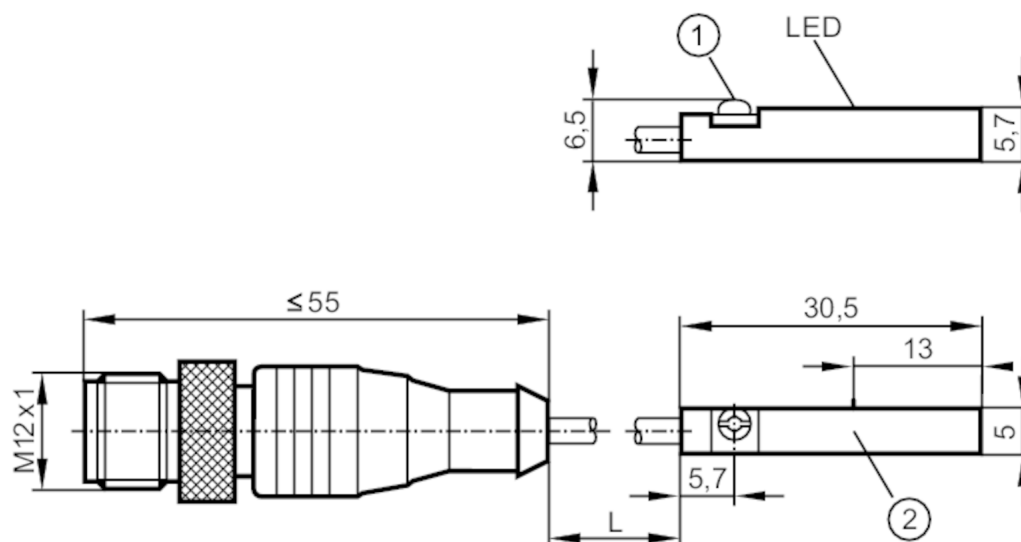

- 1 fastening clamp with combined slot / hexagon socket head
hexagonal socket AF 1.5
2 sensing face



Product characteristics

Electrical design	PNP
Output function	normally open
Dimensions [mm]	30.5 x 5 x 6.5

Electrical data

Operating voltage [V]	5...50 AC/DC; (External protective circuit for inductive load (valve, contactor, etc.) necessary. ; "supply class 2" according to UL)
Protection class	III
Reverse polarity protection	yes
Reverse polarity protection	no

Outputs

Electrical design	PNP
Output function	normally open
Max. voltage drop switching output DC [V]	1
Max. voltage drop switching output AC [V]	1
Permanent current rating of switching output AC [mA]	350
Permanent current rating of switching output DC [mA]	500
Switching frequency AC [Hz]	1000
Switching frequency DC [Hz]	1000
Max. switching power [W]	10
Short-circuit protection	no
Short-circuit proof	no

MR0121



T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

Overload protection		no	
Detection zone			
Response sensitivity	[mT]	2.1	
Travel speed	[m/s]	10	
Accuracy / deviations			
Hysteresis	[mm]	1	
Repeatability	[mm]	< 0.2	
Response times			
Max. fall time	[ms]	0.1	
Max. make time incl. bounce	[ms]	0.6	
Operating conditions			
Ambient temperature	[°C]	-25...70	
Protection		IP 65; IP 67	
Tests / approvals			
EMC	EN 61000-4-2 ESD		- CD / 8 kV AD
	EN 61000-4-3 HF radiated		10 V/m
	EN 61000-4-4 Burst		2 kV
	EN 61000-4-6 HF conducted		10 V
	EN 55011		class B
MTTF	[ANN]	20385	
UL approval		UL Approval no.	C004
Mechanical data			
Weight	[g]	21.3	
Mounting		flush mountable	
Cylinder type		T-slot cylinders	
Dimensions	[mm]	30.5 x 5 x 6.5	
Materials		PA; fastening clamp: stainless steel	
Switching cycles when connected to PLC	[Mio]	40	
Displays / operating elements			
Display		switching status	1 x LED, yellow
Electrical connection			
Required protection		miniature fuse to IEC60127-2 sheet 1; ≤ 0,75 A; fast acting; DC operation; ≤ 0,6 A; fast acting; AC operation	
Аксессуары			
Items supplied		rubber placeholder: 1	
		Cable clip: 1	
Remarks			
Pack quantity		1 pcs.	


T-slot cylinder sensor with reed contact

MRT3021BBKOA/R/0,3M/ZH/US

Electrical connection - plug

Cable: 0.3 m, PUR

Connector: 1 x M12; coding: A; Locking: knurled nut, rotatable

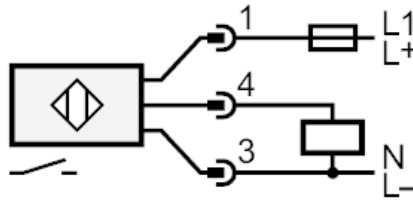

Note miniature fuse to IEC60127-2 sheet 1
 ≤ 0.75 A fast acting DC operation
 ≤ 0.6 A fast acting AC operation