


OGE-DPKG/US100



-25...60

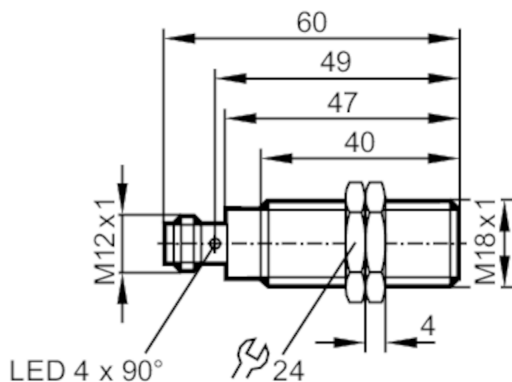

Through-beam sensor receiver

OGE-DPKG/US100

Protection	IP 67
------------	-------

Tests / approvals

EMC	EN 60947-5-2
MTTF [ANN]	1112

Mechanical data

Weight [g]	50.1
Housing	threaded type
Dimensions [mm]	M18 x 1 / L = 60
Thread designation	M18 x 1
Materials	housing: stainless steel (1.4404 / 316L)
Lens material	PMMA

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Аксессуары


Items supplied	lock nuts: 2
----------------	--------------

Remarks


Remarks	operating voltage "supply class 2" according to cULus
Pack quantity	1 pcs.

Electrical connection

Connector: 1 x M12; coding: A

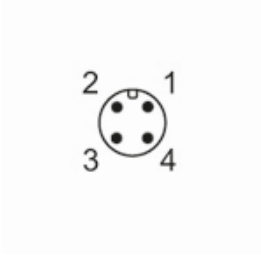

Connection

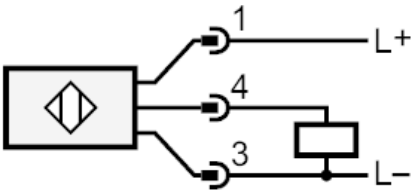



Through-beam sensor receiver

OGE-DPKG/US100

Diagrams and graphs

excess gain graph

