




Diffuse reflection sensor with background suppression

OJH-FPKG/FO/1M/US

Article no longer available - archive entry

Alternative articles: OJ5068

When selecting an alternative article and accessories please note that technical data may differ!

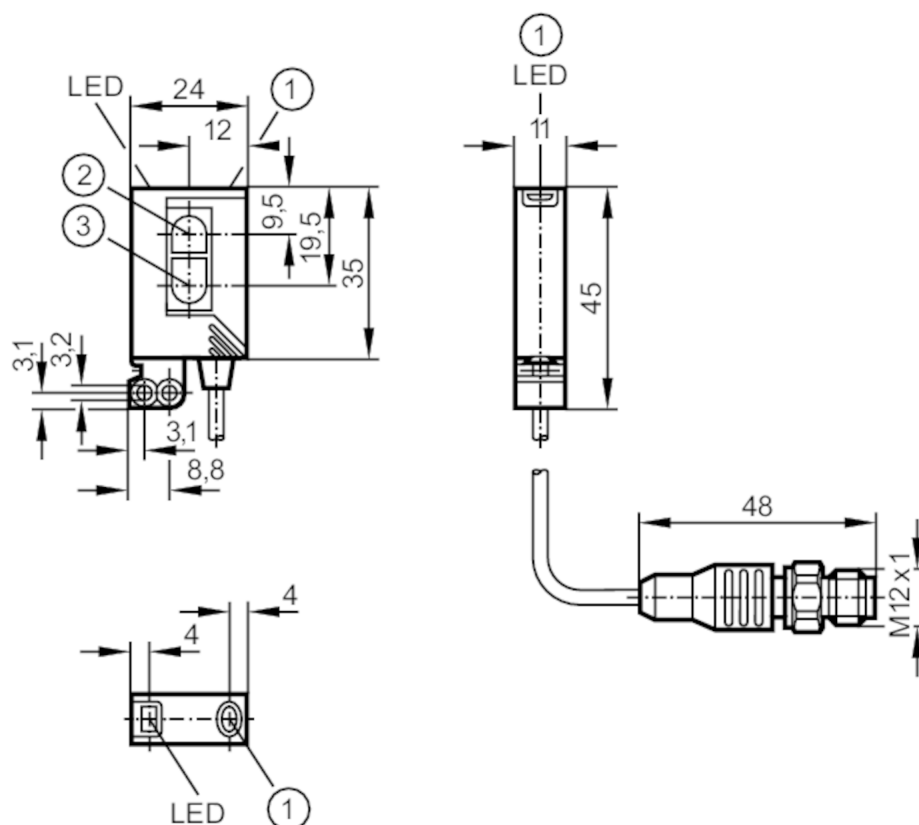

- 1 pushbutton
- 2 receiver
- 3 transmitter

Product characteristics

Type of light	red light
Housing	rectangular

Application

Special feature	Gold-plated contacts; Background suppression
Function principle	Diffuse reflection sensor

Electrical data

Operating voltage	[V]	10...30 DC
Current consumption	[mA]	25
Protection class		III
Reverse polarity protection		yes
Type of light		red light
Wave length	[nm]	660



Diffuse reflection sensor with background suppression

OJH-FPKG/FO/1M/US

Outputs		
Electrical design	PNP	
Output function	light-on/dark-on mode; (parameterisable)	
Max. voltage drop switching output DC [V]	2.5	
Permanent current rating of switching output DC [mA]	200	
Switching frequency DC [Hz]	1000	
Short-circuit protection	yes	
Type of short-circuit protection	pulsed	
Overload protection	yes	
Detection zone		
Range [mm]	15...400; (white paper 200 x 200 mm 90% remission)	
Range adjustable	yes	
Max. light spot diameter [mm]	18	
Light spot dimensions refer to	Range	
Background suppression available	yes	
Operating conditions		
Ambient temperature [°C]	-25...60	
Protection	IP 67	
Tests / approvals		
EMC	EN 60947-5-2	
Mechanical data		
Weight [g]	0.064	
Housing	rectangular	
Dimensions [mm]	35 x 24 x 11	
Materials	housing: ABS; fixture: diecast zinc; LED window: SEPS; pushbutton: SEPS	
Lens material	PMMA	
Lens alignment	front lens	
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Electronic lock	yes	
Аксессуары		
Items supplied	Basic clip: 1, E20964	
	screws: 2 x M3 x 16	
	spring washers: 2	
	Nuts: 2	
Remarks		
Remarks	operating voltage "supply class 2" according to cULus	
Pack quantity	1 pcs.	

Diffuse reflection sensor with background suppression

OJH-FPKG/FO/1M/US


Electrical connection

Cable: 1 m, PUR

Connector: 1 x M12; coding: A; Moulded body: PUR; Locking: brass; Contacts: gold-plated




Connection

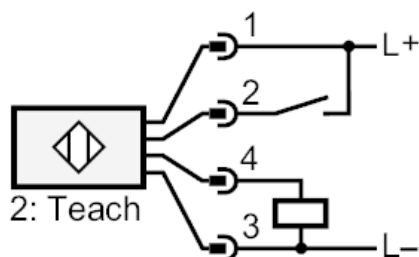

2 Teach

Diagrams and graphs

accuracy graph

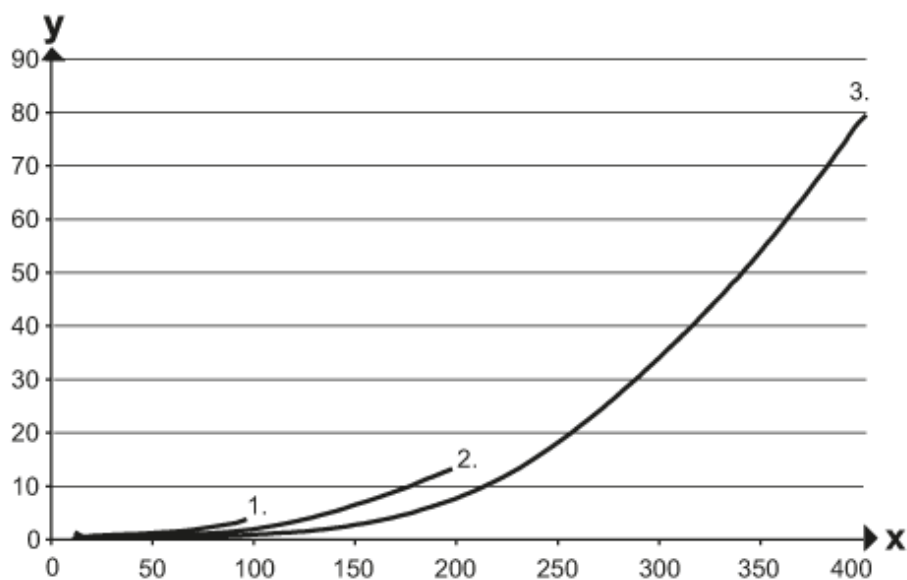


x: distance sensor/object [mm]

y: min. distance object/background [mm]

1 = object black (6 % remission) , background white (90 % remission)


2 = object grey (18 % remission) , background white (90 % remission)

3 = object white (90 % remission) , background white (90 % remission)

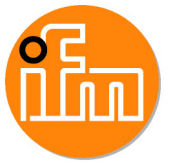

Diffuse reflection sensor with background suppression

OJH-FPKG/FO/1M/US

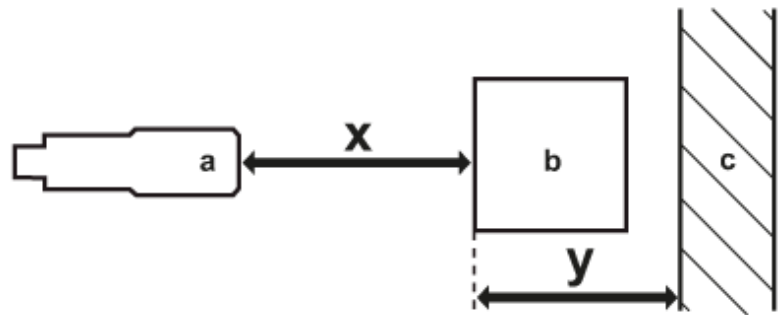

a: sensor

b: object

c: background

x: distance sensor/object [mm]

y: min. distance object/background [mm]