

PP2000



Pressure switch with ceramic measuring cell


PP-PRG- /QFRKG/US/ /

Article no longer available - archive entry

Alternative articles: PP2001

When selecting an alternative article and accessories please note that technical data may differ!

supports EPS and IO-Link communication

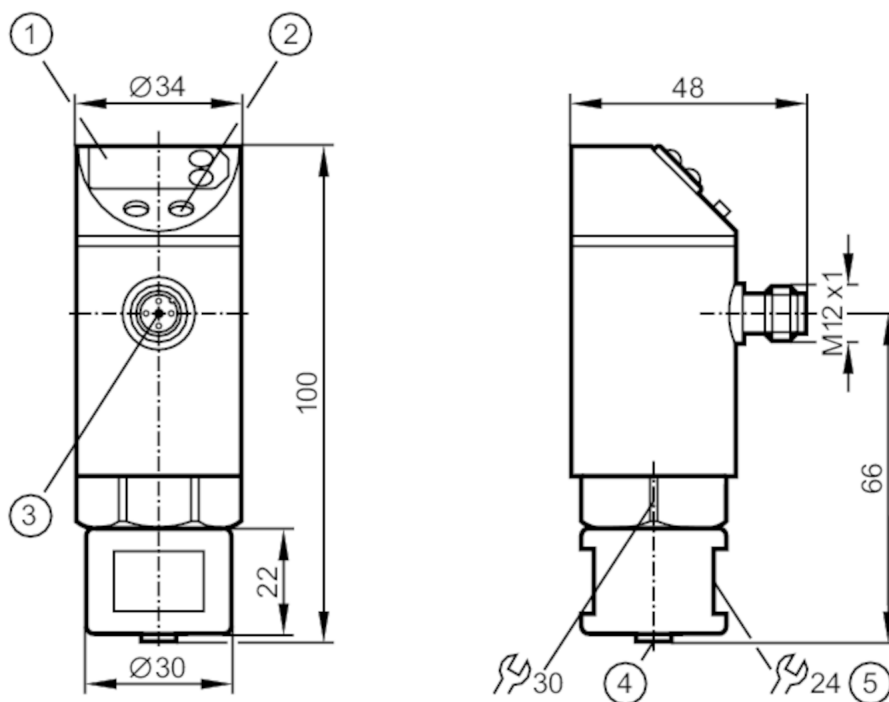

- 1 7-segment LED display
- 2 programming button
- 3 connection for voltage supply and output signals
- 4 connection for EPS sensor
- 5 mounting nut



Application

Special feature	Gold-plated contacts
Application	for industrial applications

Electrical data

Operating voltage	[V]	10.8...30 DC
Current consumption	[mA]	< 60
Min. insulation resistance	[MΩ]	100; (500 V DC)
Protection class		III
Reverse polarity protection		yes
Power-on delay time	[s]	1.5

Outputs

Output signal	switching signal
Max. voltage drop switching output DC [V]	2

PP2000



Pressure switch with ceramic measuring cell

PP-PRG- /QFRKG/US/ /

Permanent current rating of switching output DC [mA]	250
Short-circuit protection	yes
Type of short-circuit protection	pulsed
Overload protection	yes

Response times

Max. measuring/display cycle [ms]	200
-----------------------------------	-----

Software / programming

Parameter setting options	depending on the connected sensor
---------------------------	-----------------------------------

Operating conditions

Ambient temperature [°C]	-25...80
Storage temperature [°C]	-40...100
Protection	IP 67

Tests / approvals

EMC	EN 61000-4-2 ESD	4 kV CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	10 V
Shock resistance	DIN IEC 68-2-27	50 g (11 ms)
Vibration resistance	DIN IEC 68-2-6	20 g (10...2000 Hz)

Mechanical data

Weight [g]	0.378
Dimensions [mm]	100 x 34 x 48
Materials	stainless steel (1.4404 / 316L); EPDM/X; CO-PC; PBT; FKM

Displays / operating elements

Display	switching status	LED, red
	function display	7-segment LED display
	measured values	7-segment LED display

Аксессуары

Items supplied	jumper cables: 0,8 m, for parameter setting in the offline mode
----------------	---

Remarks

Pack quantity	1 pcs.
---------------	--------

PP2000




Pressure switch with ceramic measuring cell

PP-PRG- /QFRKG/US/ /

Electrical connection

Connection

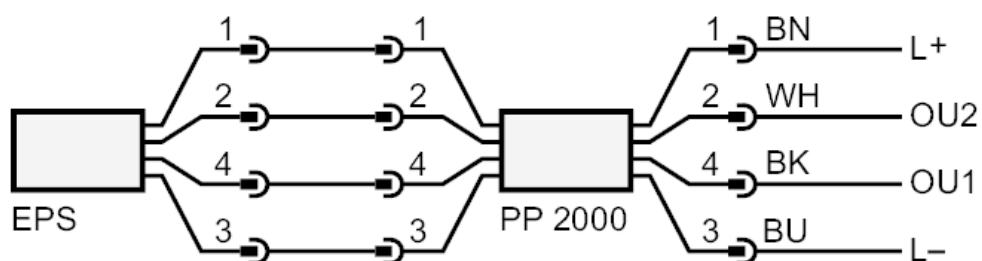

Connector: 1 x M12; Contacts: gold-plated