




On-premises licence for the advanced vibration analysis add-on - AVA

moneo RTM-AVA raw data LIC

moneo|RTM AVA Toolbox

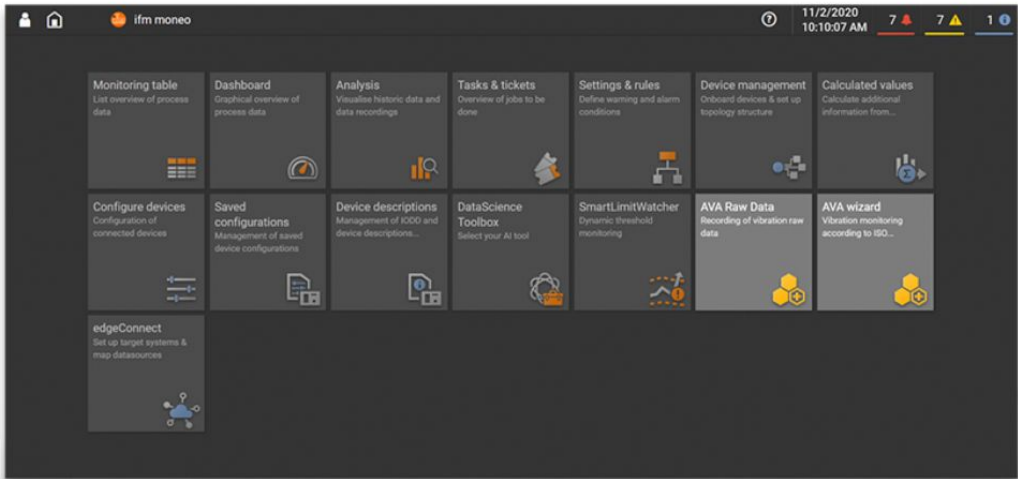

Application	
Application	moneo RTM add-on for extended vibration monitoring on machines and installations
Configuration	Condition monitoring through standardised thresholds and raw data recording
	Selection of machine parameters for monitoring on pumps, fans and compressors
	Standardised thresholds according to DIN ISO standard
	Triggering raw data recording in the event of damage based on threshold-based rules
	Additional raw data recording according to user-defined, time-based settings
Connectivity	Deactivation of thresholds and rules in case of maintenance
	Raw data recording for ifm IO-Link sensors type VVB and ifm diagnostic electronics type VSE
	Thresholds according to DIN ISO standard for ifm IO-Link sensors type VVB



On-premises licence for the advanced vibration analysis add-on - AVA

moneo RTM-AVA raw data LIC

Data management	Download of the raw data in the file formats CSV, JSON and BIN
	Maximum storage capacity of 500 raw data recordings
	When the storage capacity has been reached, the oldest raw data recordings are automatically overwritten
Monitoring	Automated ticket creation when the threshold according to DIN ISO standard has been reached
User interface	Wizard for setting up thresholds and raw data recording
	visualisation of vibration data in the time and frequency range
Analysis	analysis of specific frequencies for advanced vibration diagnostics
Software / programming	
Language	German; English; French; Italian; Spanish; Portuguese; Chinese; Japanese; Korean; Польська
Data carrier	download
Type of licence	single licence
Licence class	on-premises full version
System requirements	
Additionally required software	moneo software download
	moneo OS license
	moneo RTM license
	moneo edgeConnect AL
	moneo infopoints