


## Airflow monitor

LTM1202B1A

Article no longer available - archive entry

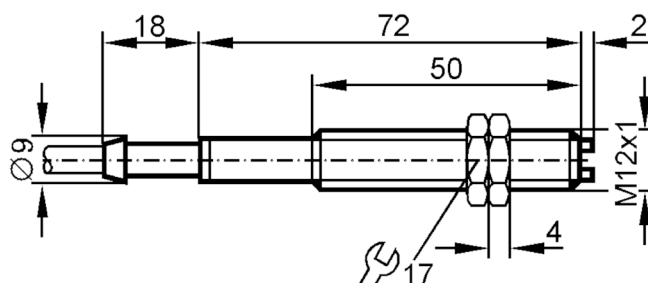

## Product characteristics

Process connection	M12 x 1
--------------------	---------

## Application

Pressure rating	[bar]	5
-----------------	-------	---

## Electrical data

Connection to switching amplifiers	yes	
Switching amplifiers	Connection to control monitor SC0001	
Power-on delay time	[s]	60

## Measuring/setting range

## Gases

Setting range	[cm/s]	10...2000
Greatest sensitivity	[cm/s]	10...250

## Accuracy / deviations

Temperature gradient	[K/min]	15
----------------------	---------	----

## Response times

Response time	[s]	< 5
---------------	-----	-----

## Gases

Response time	[s]	< 5
---------------	-----	-----

## Operating conditions

Protection	IP 67
------------	-------

## Mechanical data

Dimensions	[mm]	M12 x 1
Thread designation		M12 x 1

SL0002



Airflow monitor

LTM1202B1A

Materials	brass nickel-plated
Materials (wetted parts)	sensor surface: PBT
Process connection	M12 x 1

Аксессуары

Items supplied	lock nuts: 2
----------------	--------------


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 2 m, PUR; 3 x 0.34 mm<sup>2</sup>

Connection

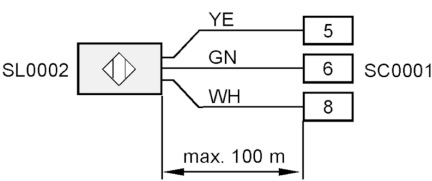

Core colours :  
YE = yellow  
GN = green  
WH = white