


Adapter for LB conduit

CONDUIT ADPTR, DUAL M12, 3/4"

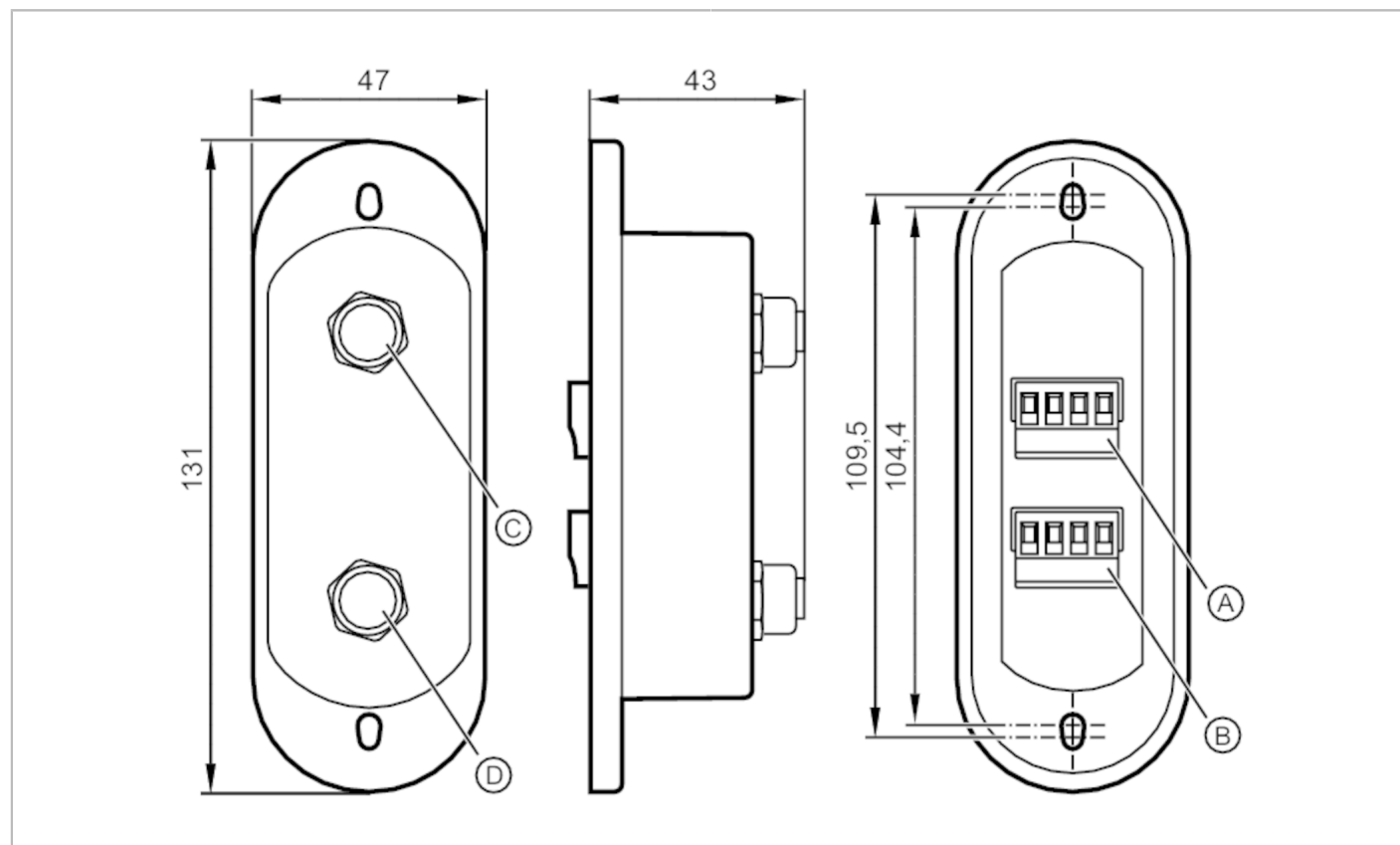

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage	[V]	< 300 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...70
---------------------	------	----------

Mechanical data

Weight	[g]	272.155
Materials	housing: PBT-GF20; Sealing: NBR	
Number of ports splitter box	2	

Remarks

Pack quantity	1 pcs.
---------------	--------




Adapter for LB conduit

CONDUIT ADPTR, DUAL M12, 3/4"

Electrical connection - socket

Connector: 2 x M12; coding: A; Contacts: gold-plated

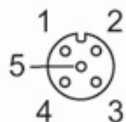

Connection

