


ZH4118



Connecting cable with plug

ASTGH120MSS0005K12

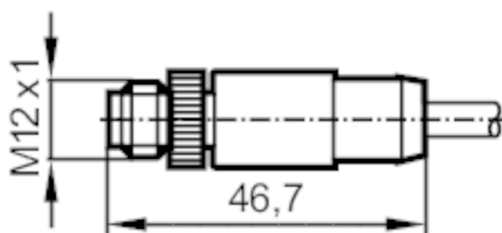

Application

Special feature	Gold-plated contacts; Screened cable
-----------------	--------------------------------------

Electrical data

Operating voltage	[V]	< 30 AC/DC
Protection class		II
Max. current load total	[A]	1.5

Operating conditions

Ambient temperature	[°C]	-30...80
Ambient temperature (moving)	[°C]	-5...80
Protection		IP 67

Mechanical data

Weight	[g]	551
Dimensions	[mm]	14.5 x 14.5 x 48.5
Materials		TPU
Moulded-body material		TPU
Material nut		zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

ZH4118



Connecting cable with plug


ASTGH120MSS0005K12

Electrical connection

Cable: 5 m, PUR, black, Ø 6.5 mm, shielded; 12 x 0.14 mm² (18 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.4 Nm

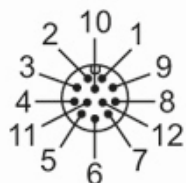

Connection