


AC1057



AS-Interface gateway

Master S7-300 CP343-2 6GK7 343

Article no longer available - archive entry

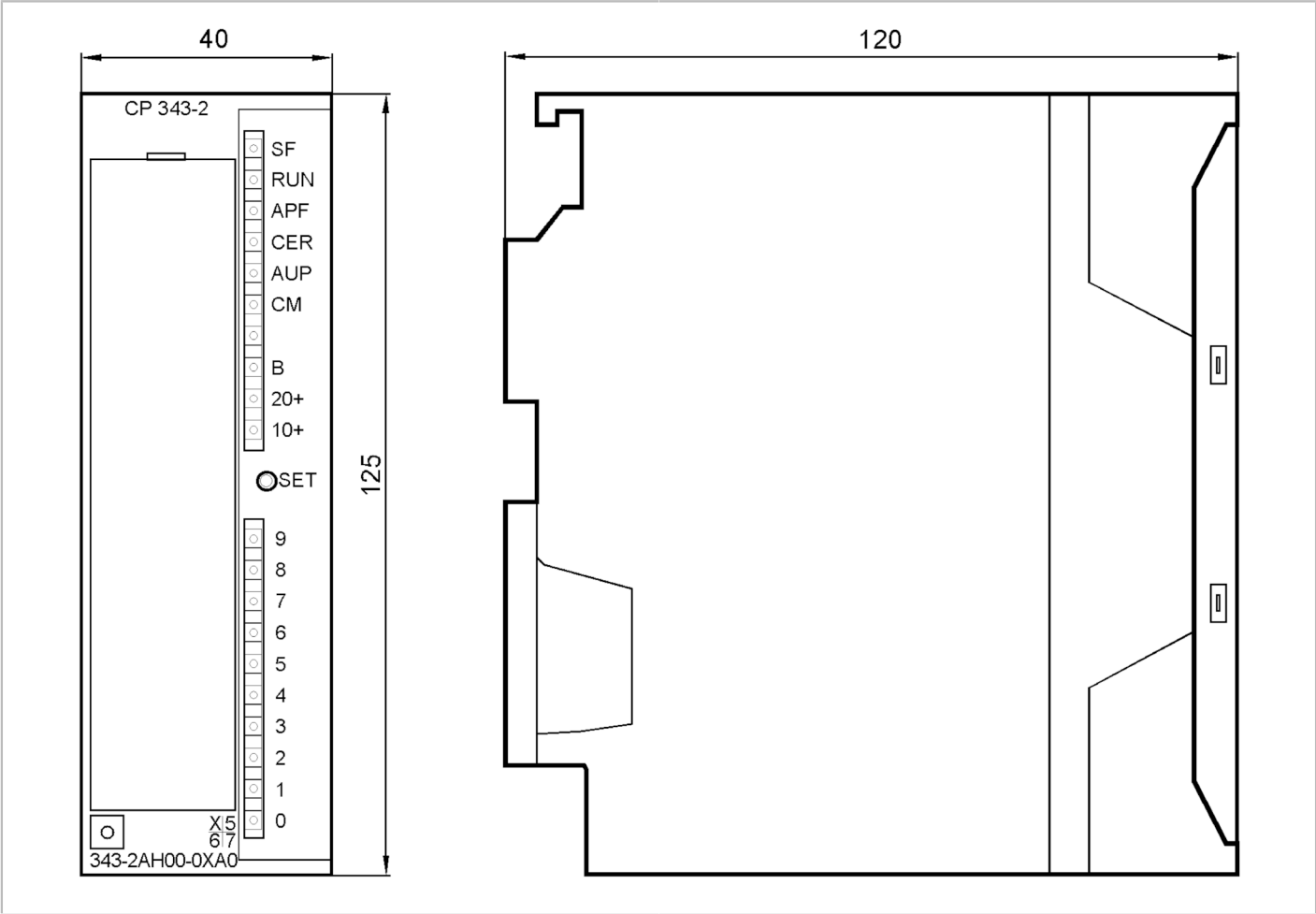

Application		
Application		connection to medium-range control systems
Electrical data		
Operating voltage	[V]	5 DC; (via backplane bus)
Current consumption	[mA]	200; (via backplane bus)
Max. current consumption from AS-i	[mA]	40
Number of AS-i masters		1
Interfaces		
Communication interface		S7-300
Operating conditions		
Ambient temperature	[°C]	0...60
Protection		IP 20
AS-i classification		
AS-i version		2.1
AS-i master profile		M1

AC1057



AS-Interface gateway

Master S7-300 CP343-2 6GK7 343

Mechanical data	
Material	PBT
Accessories	
Accessories (optional)	Front plug:, E70126
	Manual:, German, AC1056
	Manual:, English, AC1059
Remarks	
Remarks	Access to AS-i peripheral equipment in the same way as to standard peripheral equipment.
	Existing programmes can still be used.
Pack quantity	1 pcs.