


AC1150



AS-Interface module for frequency converter

2DI RS485 SEW CCT

Article to be discontinued

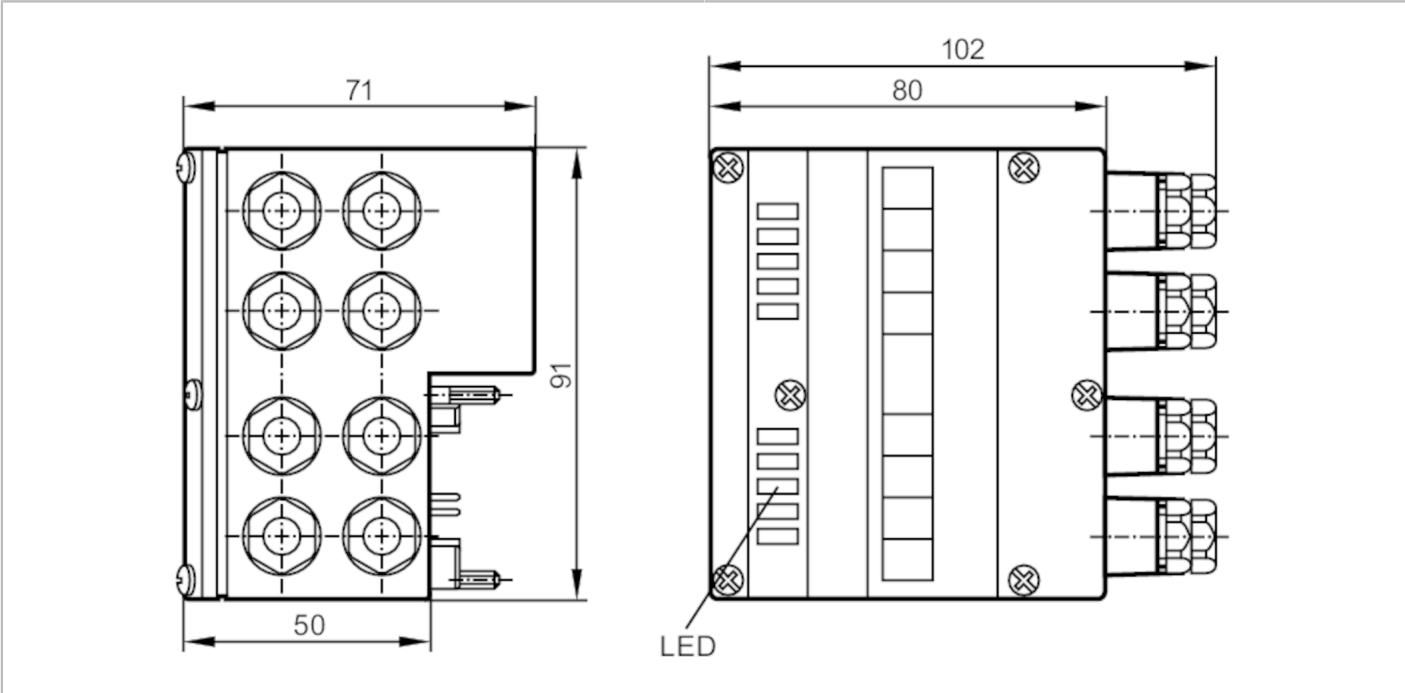

Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	80
Reverse polarity protection		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AUX
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	26
Input current High	[mA]	> 5
Input current low	[mA]	< 1
Operating conditions		
Ambient temperature	[°C]	0...55
Protection		IP 65
Tests / approvals		
EMC	EN 50295	

AC1150



AS-Interface module for frequency converter

2DI RS485 SEW CCT

AS-i classification					
AS-i master profile	M2; M3; M4				
AS-i profile	S-7.F				
AS-i I/O configuration	[hex]	7			
AS-i ID code	[hex]	F			
Data bits	Data bit	D0	D1	D2	D3
	Function	motor stopped/ running	Error message	input 1	input 2
Mechanical data					
Weight	[g]	286.7			
Type of mounting		AS-i interface to FC-E lower parts			
Material		PBT			
Displays / operating elements					
Display	Switching status			LED, yellow	
	Power			LED, green	
	short circuit			LED, red	
	Function			LED, red	
Remarks					
Pack quantity		1 pcs.			
Electrical connection					
contact pins to module lower part, FK-E:					