




AS-Interface PROFIBUS DP gateway

ASI DP GATEWAY 2 MASTER

Article no longer available - archive entry

Alternative articles: AC1376
When selecting an alternative article and accessories please note that technical data may differ!

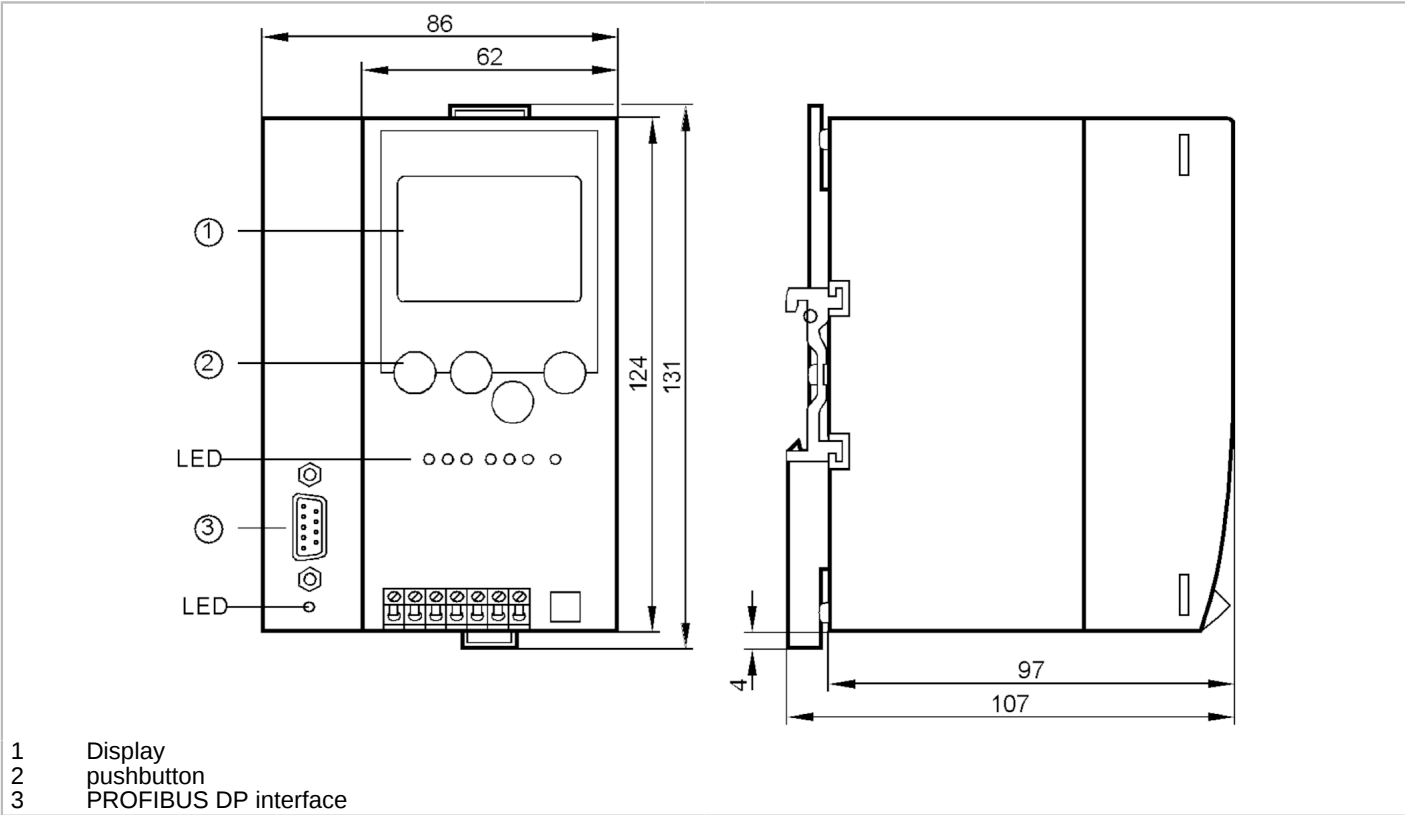

Application	
Application	PROFIBUS DP gateway
Electrical data	
Operating voltage	[V] 24 DC; (cULus - Class 2 source required)
Insulation rating	[V] 500
Current consumption	[mA] < 400
Max. current consumption from AS-i	[mA] 10
Max. power consumption	[VA] 10
Number of AS-i masters	2
Electrical separation	yes
Interfaces	
Communication interface	PROFIBUS
PROFIBUS	
Transmission standard	EN 50170
Transmission rate	12 MBaud
Protocol	Profibus DP
Usage type	Data transmission



AS-Interface PROFIBUS DP gateway

ASI DP GATEWAY 2 MASTER

Note on interfaces		Diagnostic function	
Operating conditions			
Ambient temperature	[°C]	0...60	
Storage temperature	[°C]	-20...70	
Max. relative air humidity	[%]	95	
Protection		IP 20	
AS-i classification			
AS-i version		2.1	
AS-i master profile		M3	
AS-i certificate		61106	
Mechanical data			
Housing		housing for DIN rail mounting	
Dimensions	[mm]	86 x 131 x 107	
Material		aluminum; steel sheet galvanized	
Displays / operating elements			
Display	Power	3 x LED, red	
		3 x LED, green	
		2 x LED, yellow	
		full graphic LCD display	
Remarks			
Pack quantity		1 pcs.	
Electrical connection			
Connection			

