

AC1335




AS-Interface PROFIBUS DP gateway

AS-i DP Gateway 1 Master

Article no longer available - archive entry

Alternative articles: AC1375
When selecting an alternative article and accessories please note that technical data may differ!

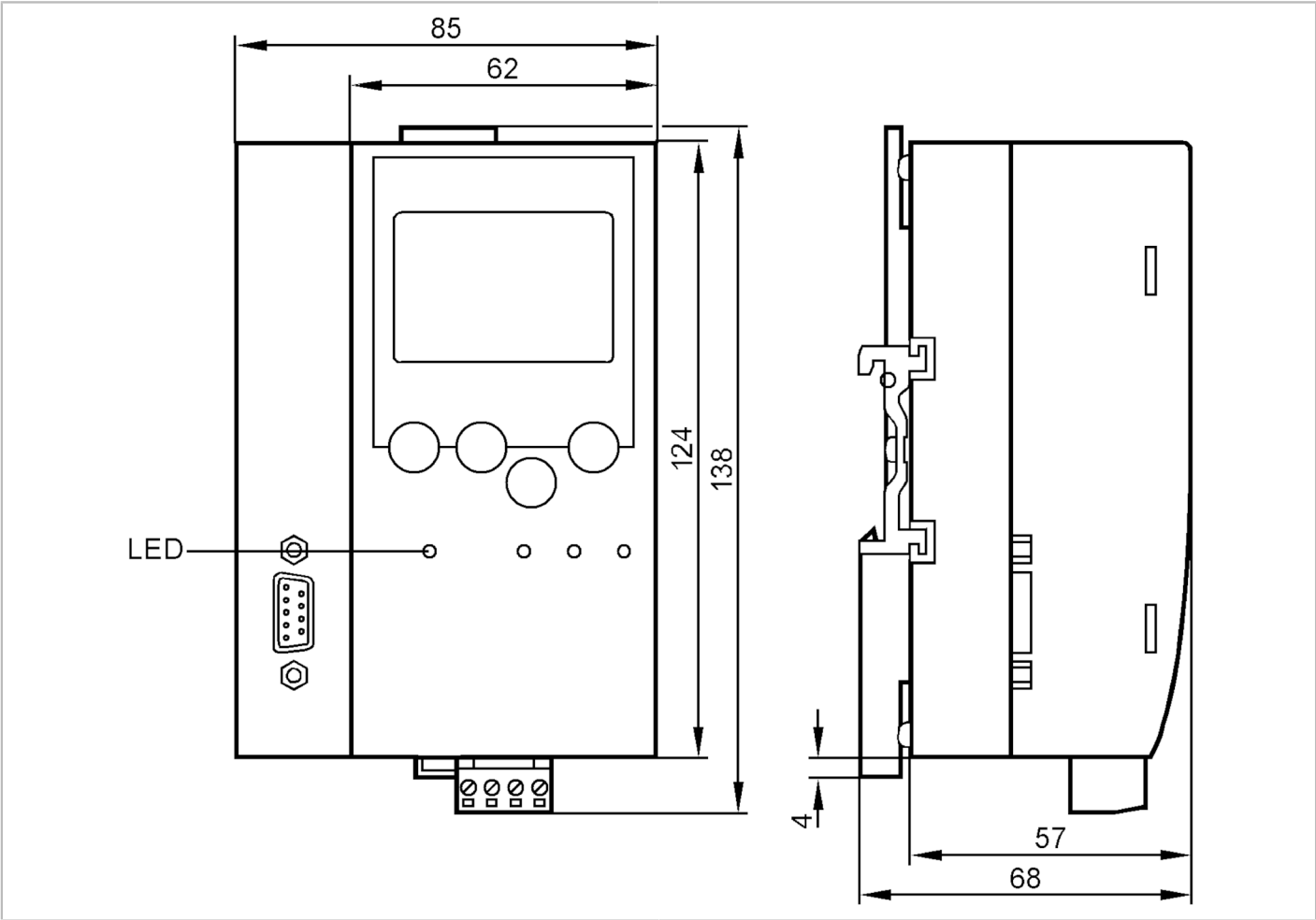

Application	
Application	PROFIBUS DP gateway
Electrical data	
Operating voltage	[V] 26.5...31.6 DC; (AS-i)
Insulation rating	[V] 500
Max. current consumption from AS-i	[mA] 200
Max. power consumption	[VA] 4
Number of AS-i masters	1
Electrical separation	yes
Outputs	
Electrical design	AS-i
Interfaces	
Communication interface	PROFIBUS



AS-Interface PROFIBUS DP gateway

AS-i DP Gateway 1 Master

PROFIBUS	
Transmission standard	EN 50170
Transmission rate	12 MBaud
Protocol	Profibus DP
Usage type	Data transmission
Note on interfaces	Diagnostic function

Operating conditions	
Ambient temperature [°C]	0...60
Storage temperature [°C]	-20...70
Max. relative air humidity [%]	95
Protection	IP 20


AS-i classification	
AS-i version	2.1
AS-i master profile	M3
AS-i certificate	63501

Mechanical data	
Housing	housing for DIN rail mounting
Material	aluminum; steel sheet galvanized

Displays / operating elements		
Display	Function	2 x LED, red
		1 x LED, green
		1 x LED, yellow
		full graphic LCD display

Remarks	
Pack quantity	1 pcs.

Electrical connection	
Connection	

 

AS-i AS-i n.c. FE
1+ 1-