

AC2500




AS-Interface ClassicLine module

ClassicLine45 4 SB

Article no longer available - archive entry

Alternative articles: AC5200
When selecting an alternative article and accessories please note that technical data may differ!

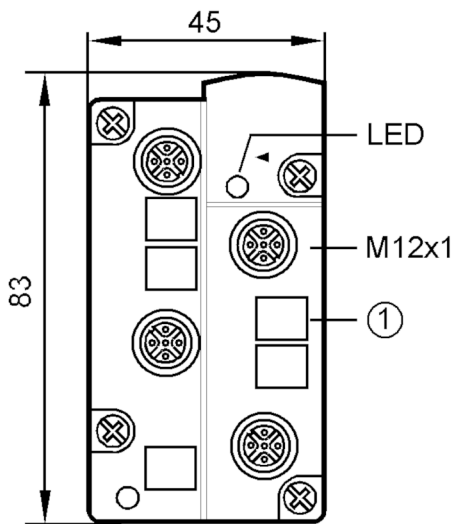

1 panel for labelling



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2
Inputs		
Voltage supply	[V]	20...30
Outputs		
Electrical design		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Weight	[g]	100.4
Type of mounting		AS-i interface to FC lower parts
Material		PBT
Accessories		
Accessories (optional)		Module lower part
Remarks		
Pack quantity		1 pcs.




AS-Interface ClassicLine module

ClassicLine45 4 SB

Electrical connection

Connector: M12; coding: A

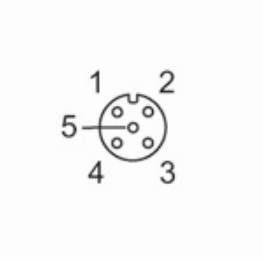

1	AS-i +
2	External voltage -
3	AS-i -
4	External voltage +