

AC2605




AS-Interface control cabinet module

AnalogModule 1A0 ST

Article no longer available - archive entry

Alternative articles: AC2611

When selecting an alternative article and accessories please note that technical data may differ!

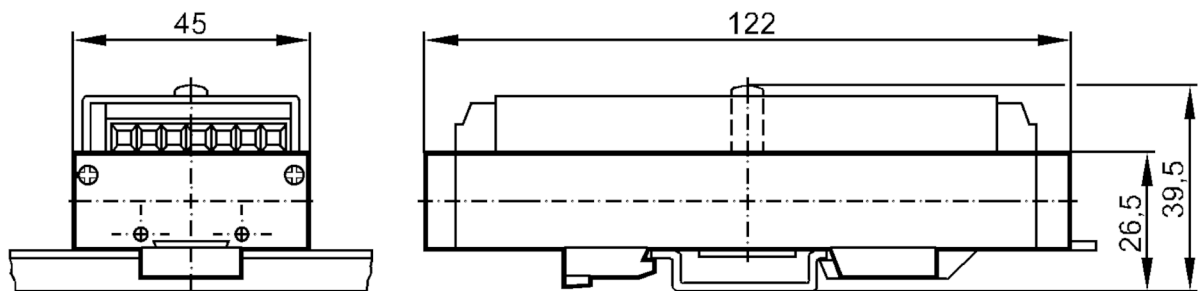

Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	135
Outputs		
Electrical design		AS-i
Voltage range DC	[V]	13...36; (to PELV)
Max. current load per output	[mA]	100
Short-circuit proof		yes
Operating conditions		
Ambient temperature	[°C]	0...70
Protection		IP 20
Tests / approvals		
EMC	EN 50295	
AS-i classification		
AS-i profile		S-7.1
AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	1
Mechanical data		
Type of mounting	Mounting on DIN rail and panel; String mounting possible	

AC2605



AS-Interface control cabinet module

AnalogModule 1A0 ST

Material	PA; PVC
----------	---------

Displays / operating elements

Display	Power	LED, green
	Function	1 x LED, yellow
		1 x LED, red


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

screw terminals:

Connection

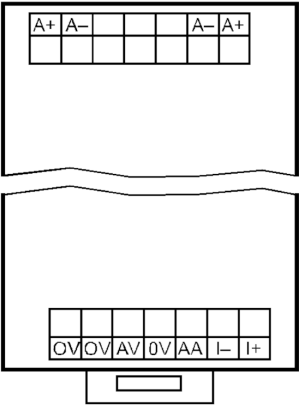

A+	AS-i +
A-	AS-i -
I+	Actuator supply +24V
I-	Actuator supply 0V
AA	analog output +
0V	analog output 0V