

AC2010




AS-Interface illuminated pushbutton module

Moduloberteil aktiv,

Article no longer available - archive entry

Alternative articles: AC2018

When selecting an alternative article and accessories please note that technical data may differ!

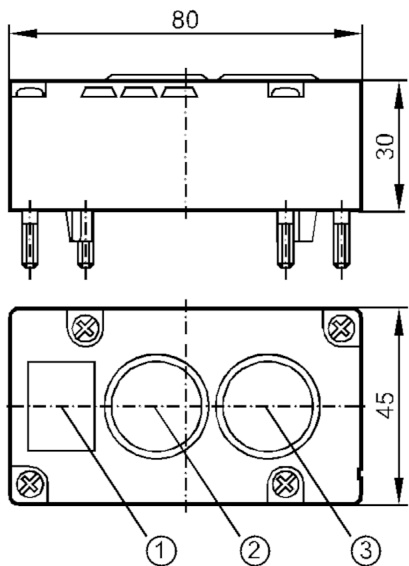

- 1 panel for labelling
- 2 pushbutton / LED green
- 3 pushbutton / LED red



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 55

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature	[°C]	-25...60
Protection		IP 67

Tests / approvals

EMC	EN 50295
-----	----------

AS-i classification

AS-i profile	S-3.F				
AS-i I/O configuration	[hex]	3			
AS-i ID code	[hex]	F			
Data bits	Data bit	D0	D1	D2	D3
	pushbutton	2	1	-	-
	LED	-	-	2	1



AS-Interface illuminated pushbutton module

Moduloberteil aktiv,

Mechanical data	
Type of mounting	AS-i interface to FC and SC lower parts
Material	PBT
Remarks	
Remarks	The pushbuttons (EAO type 84) provide protection against accidental contact. Housing and pushbuttons can be labeled.
Pack quantity	1 pcs.
Electrical connection	
contact pins to module lower part, FK / PG:	