




AS-Interface module

Moduloberteil aktiv, 4AT PNP 1

Article no longer available - archive entry

Alternative articles: AC5208
When selecting an alternative article and accessories please note that technical data may differ!

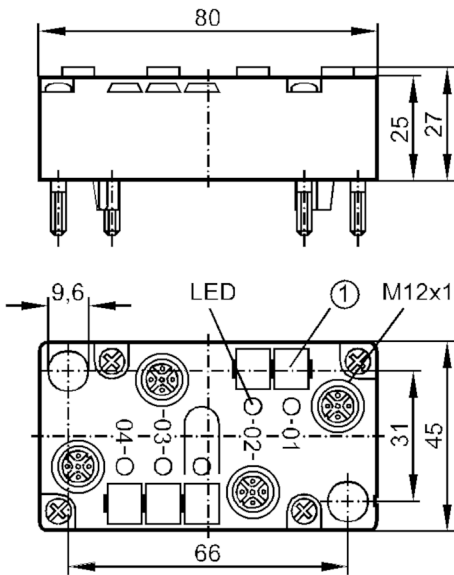

1 panel for labelling

 


Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 35
Max. current load total	[A]	2
Integrated watchdog		no
Inputs / outputs		
Number of inputs and outputs		Number of digital outputs: 4
Outputs		
Electrical design		AS-i
Number of digital outputs		4
Circuit		PNP
Voltage range DC	[V]	24; (to PELV; via M12 connector)
Max. current load per output	[mA]	1000; (DC-12)
Short-circuit proof		yes
Electrically separated		yes
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67



AS-Interface module

Moduloberteil aktiv, 4AT PNP 1

Tests / approvals						
EMC		EN 50295				
AS-i classification						
AS-i profile		S-8.0				
AS-i I/O configuration [hex]		8				
AS-i ID code [hex]		0				
AS-i certificate		04301				
Data bits		Data bit	D0	D1	D2	D3
		Socket	O-1	O-2	O-3	O-4
		Pin	4	4	4	4
Mechanical data						
Type of mounting		AS-i interface to FC lower parts				
Material		PBT				
Displays / operating elements						
Display		Power		LED, green		
		Function		LED, yellow		
Remarks						
Pack quantity		1 pcs.				
Electrical connection						
contact pins to module lower part, FK / PG:						
Connector: M12; coding: A						
Connector: M12; coding: A						
 1 External voltage + 3 External voltage -						