




AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Article no longer available - archive entry

Alternative articles: AC5215
When selecting an alternative article and accessories please note that technical data may differ!

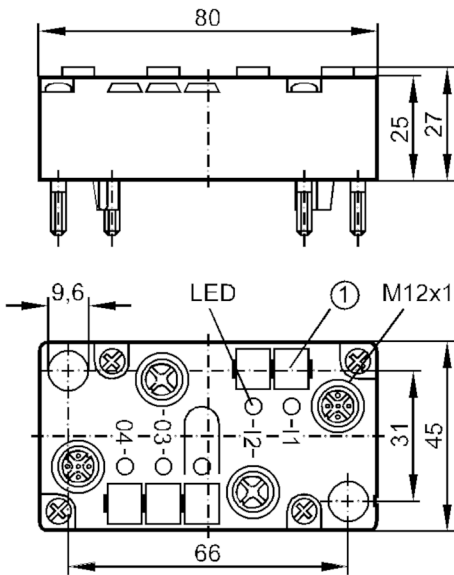

1 panel for labelling



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Inputs / outputs		
Number of inputs and outputs	Number of digital inputs: 4	
Inputs		
Number of digital inputs	4; (2 x 2)	
Input circuit of digital inputs	PNP	
Sensor supply of the inputs	AS-i	
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	> 5
Input current low	[mA]	< 1.5
Switching level high	[V]	> 10
Digital inputs protected against short circuits	yes	
Outputs		
Electrical design	AS-i	



AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Operating conditions						
Ambient temperature		[°C]		-25...85		
Protection		IP 67				
Tests / approvals						
EMC		EN 50295				
AS-i classification						
AS-i profile		S-0.1				
AS-i I/O configuration		[hex]		0		
AS-i ID code		[hex]		1		
AS-i certificate		01302				
Data bits		Data bit	D0	D1	D2	D3
		Socket	I-1/2	I-1/2	I-3/4	I-3/4
		Pin	4	2	4	2
Mechanical data						
Type of mounting		AS-i interface to FC lower parts				
Material		PBT				
Displays / operating elements						
Display		Power		LED, green		
		Function		LED, yellow		
Remarks						
Pack quantity		1 pcs.				
Electrical connection						
contact pins to module lower part, FK / PG:						
Connector: M12; coding: A						
