

AC2034




AS-Interface universal module

EEMS/Module/4DO/T/CCT

Article no longer available - archive entry

Alternative articles: AC2035

When selecting an alternative article and accessories please note that technical data may differ!

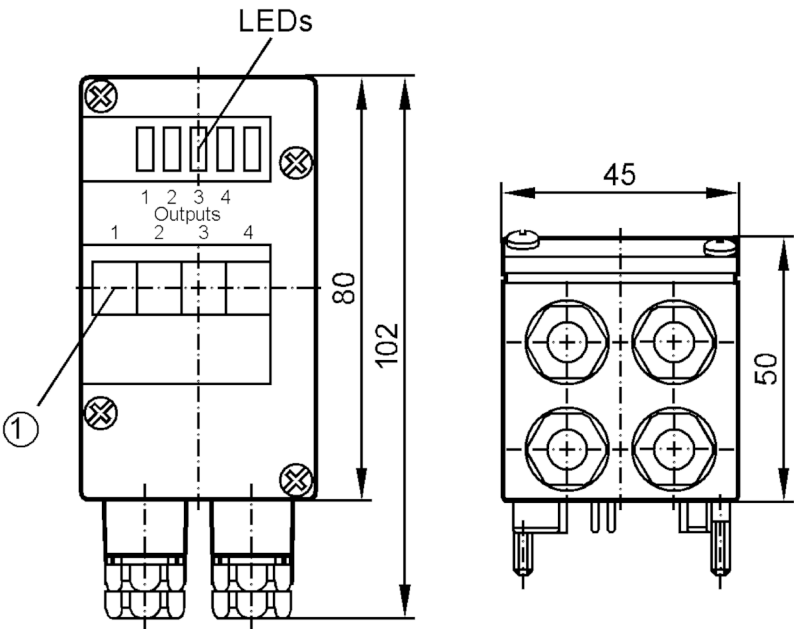

1 panel for labelling



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 60
Max. current load total	[A]	4
Integrated watchdog		yes

Inputs / outputs

Number of inputs and outputs	Number of digital outputs: 4
------------------------------	------------------------------

Outputs

Electrical design	AS-i
Number of digital outputs	4
Circuit	PNP
Voltage range DC	[V] 24; (to PELV)
Max. current load per output	[mA] 1000
Short-circuit proof	yes
Electrically separated	yes

Operating conditions

Ambient temperature	[°C] -25...60
Protection	IP 65



AS-Interface universal module

EEMS/Module/4DO/T/CCT

Tests / approvals							
EMC		EN 50295					
AS-i classification							
AS-i profile		S-8.0					
AS-i I/O configuration [hex]		8					
AS-i ID code [hex]		0					
Data bits		Data bit	D0	D1	D2	D3	
		Description	O-1	O-2	O-3	O-4	
Parameter bits		Parameter bit	Function				
		P0	watchdog for all outputs	:	activated	* /	disabled
		P1	not used				
		P2	not used				
		P3	not used				
Mechanical data							
Type of mounting		AS-i interface to FC-E or SC lower parts					
Material		PA 6-GF30; stainless steel (1.4305 / 303)					
Displays / operating elements							
Display		Power			LED, green		
		Function			LED, yellow		
Remarks							
Pack quantity		1 pcs.					
Electrical connection							
cage clamps:							
contact pins to module lower part, FK-E / PG:							