




AS-Interface illuminated pushbutton module

EMS-Module 2BI 2LO YE/YE

Article no longer available - archive entry

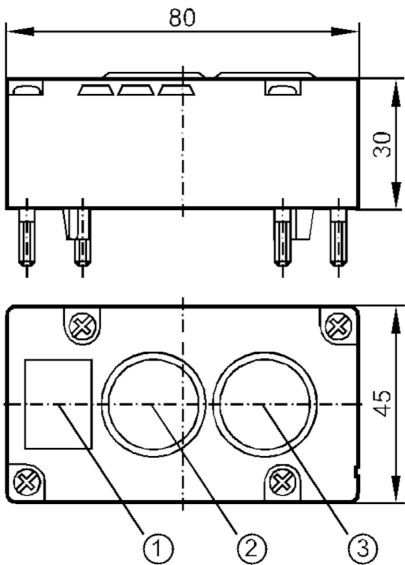

- 1 panel for labelling
- 2 pushbutton / LED yellow
- 3 pushbutton / LED yellow



Electrical data						
Operating voltage		[V]	26.5...31.6 DC			
Current consumption		[mA]	< 55			
Outputs						
Electrical design			AS-i			
Operating conditions						
Ambient temperature		[°C]	-25...60			
Protection			IP 67			
Tests / approvals						
EMC		EN 50295				
AS-i classification						
AS-i profile		S-3.F				
AS-i I/O configuration		[hex]	3			
AS-i ID code		[hex]	F			
AS-i certificate		04501				
Data bits		Data bit	D0	D1	D2	D3
		pushbutton	2	1	-	-
		LED	-	-	2	1
Mechanical data						
Type of mounting		AS-i interface to FC and SC lower parts				

AC2045



AS-Interface illuminated pushbutton module

EMS-Module 2BI 2LO YE/YE

Material	PBT
Remarks	
Remarks	The pushbuttons (EAO type 84) provide protection against accidental contact. Housing and pushbuttons can be labeled.
Pack quantity	1 pcs.
Electrical connection	
contact pins to module lower part, FK / PG:	
Connector: M12; coding: A	