


AC2057



AS-Interface Airbox

AirBox 2DI 1PO M12 V2A

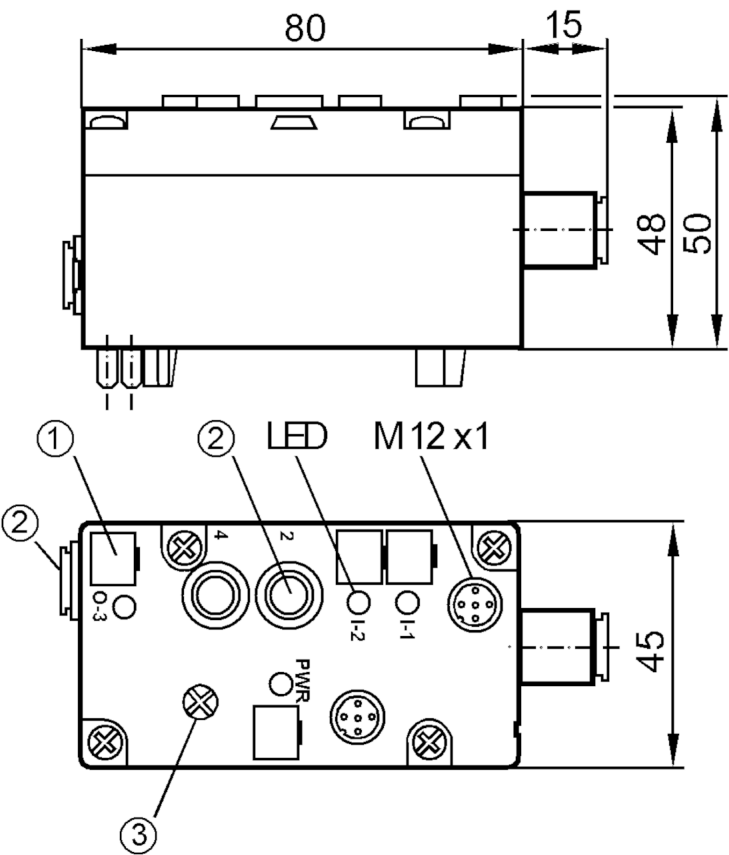

- 1 panel for labelling
- 2 tube connection Ø 8 mm
- 3 screw for manual override



Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	165
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2; Number of pneumatic outputs: 1
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	100
Input current High	[mA]	> 3



AS-Interface Airbox

AirBox 2DI 1PO M12 V2A

Input current low	[mA]	< 1.5				
Switching level high	[V]	> 10				
Digital inputs protected against short circuits		yes				
Outputs						
Number of pneumatic outputs		1; (pneumatic NO/NC selectable output ; monostable)				
Actuator supply outputs		AS-i				
Operating conditions						
Ambient temperature	[°C]	0...55				
Note on ambient temperature		with special compressed air treatment: < 0 °C				
Protection		IP 67				
Tests / approvals						
EMC		EN 50295				
AS-i classification						
Extended addressing mode		no				
AS-i master profile		M2; M3; M4				
AS-i profile		S-3.F				
AS-i I/O configuration	[hex]	3				
AS-i ID code	[hex]	F				
Data bits		Data bit	D0	D1	D2	D3
		Inputs / outputs	I-1	I-2	O-3	not used
Mechanical data						
Weight	[g]	249.85				
Type of mounting		screw mounting				
Material		housing: PBT; metal parts: stainless steel (1.4305 / 303); sealing: FKM				
Pneumatic system		1 x 4/2-way seat valve				
Operating pressure range	[bar]	3...8				
Operating pressure range	[MPa]	0.3...0.8				
Note on working pressure range		incl. possible pressure peaks				
Air flow at 6/5 bar	[l/min]	500				
Air flow at 6/0 bar	[l/min]	700				
Permissible compressed air		filtered (5 µm); lubricated (ISO-VG10) or not lubricated				
Tube fittings		Legris LF 3000/8				
Exhaust		exhaust can be discharged through tube connection				
Displays / operating elements						
Display		Power	LED, green			
		Function	LED, yellow			
Accessories						
Accessories (optional)		Silencer:, E75232				
Remarks						
Remarks		Please see the notes on compressed air and EMC/ESD under "Downloads"				
Pack quantity		1 pcs.				




AS-Interface Airbox

AirBox 2DI 1PO M12 V2A

Electrical connection

contact pins to module lower part, FK / PG:

Connection

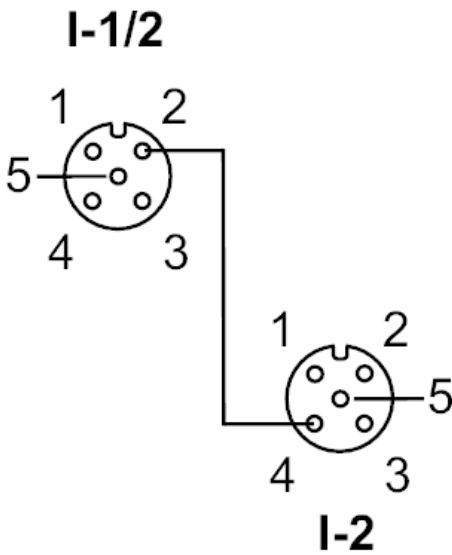

	Input
	Socket I-1/2
1	Sensor supply L+
2	Data input 2
3	Sensor supply L-
4	Data input 1
5	not used
	Socket I-2
1	Sensor supply L+
2	not used
3	Sensor supply L-
4	Data input 2
5	not used