

AC2210




AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Article no longer available - archive entry

Alternative articles: AC2257
When selecting an alternative article and accessories please note that technical data may differ!

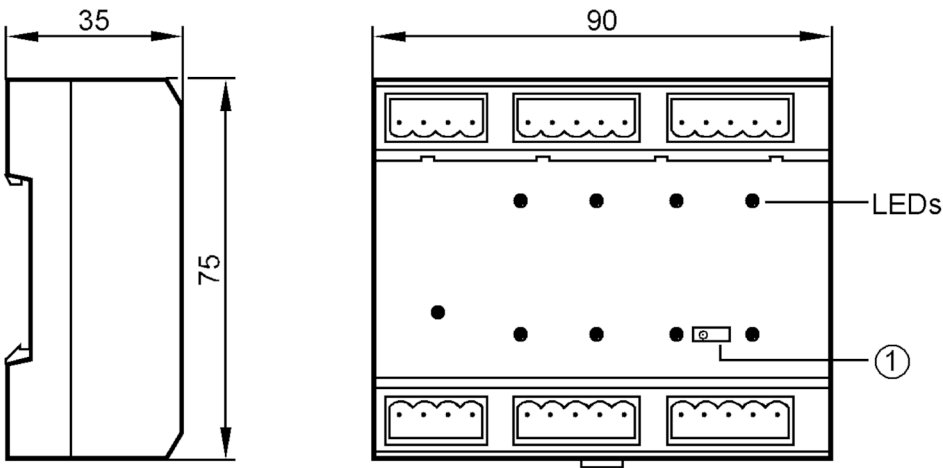

1 Addressing socket



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Max. current load total	[A]	6
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 4; Number of digital outputs: 4
Inputs		
Number of digital inputs		4; (bidirectional)
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	> 5
Input current low	[mA]	< 1.5
Switching level high	[V]	> 10
Digital inputs protected against short circuits		yes



AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Outputs		
Electrical design	AS-i	
Number of digital outputs	4	
Circuit	PNP	
Voltage range DC [V]	10...30; (to PELV)	
Max. current load per output [mA]	2000	
Short-circuit proof	yes	
Electrically separated	yes	
Operating conditions		
Ambient temperature [°C]	-25...80	
Protection	IP 20	
Tests / approvals		
EMC	EN 50295	
AS-i classification		
AS-i profile	S-7.0	
AS-i I/O configuration [hex]	7	
AS-i ID code [hex]	0	
AS-i certificate	05001	
Mechanical data		
Type of mounting	Mounting on DIN rail	
Material	PA; PVC	
Displays / operating elements		
Display	Switching status	LED, yellow
	Power	LED, green
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Connection		

