


AS-Interface control cabinet module

SmartL25 4DI C

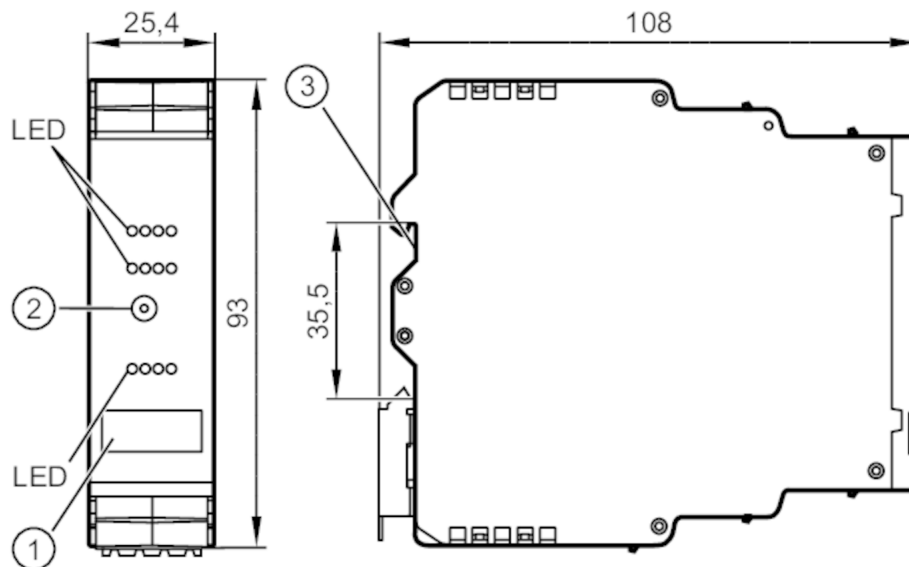

- 1 panel for labelling
- 2 Addressing socket
- 3 DIN rail adapter



Application

Application	I/O modules for control cabinet installations
-------------	---

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	50
Additional voltage supply	[V]	20...30 DC; (AUX)
Max. current consumption from additional supply	[mA]	600; (AUX)

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

Inputs

Number of digital inputs		4
Input circuit of digital inputs		PNP; (type 2 according to IEC 61131-2)
Sensor supply of the inputs		AUX
Voltage supply	[V]	18...30; (DC)
Max. total current rating of inputs	[mA]	500
Input current High	[mA]	6...10
Input current low	[mA]	0...2



AS-Interface control cabinet module

SmartL25 4DI C

Switching level high	[V]	> 11				
Digital inputs protected against short circuits		yes				
Operating conditions						
Ambient temperature	[°C]	-25...70				
Max. relative air humidity	[%]	90; (non condensing)				
Max. height above sea level	[m]	2000				
Protection		IP 20				
Degree of soiling		2				
Tests / approvals						
EMC		EN 61000-6-2				
		EN 62026-2				
		EN 50581				
MTTF	[years]	485				
Notes		The device shall be supplied from an isolating source.; This voltage source must have a secondary UL-listed fuse (see enclosed sheet).; Alternatively, a class 2 power supply can be used to supply AUX.				
AS-i classification						
AS-i version		2.11; 3.0				
AS-i addressing		Addressing socket				
Extended addressing mode		yes				
AS-i master profile		M2; M3; M4				
AS-i profile		S-0.A.E				
AS-i I/O configuration	[hex]	0				
AS-i ID code	[hex]	A.E				
AS-i certificate		39402				
Data bits	Data bit	D0	D1	D2	D3	
	Input	I-1	I-2	I-3	I-4	
Mechanical data						
Weight	[g]	142				
Type of mounting		Mounting on DIN rail				
Material		PC-GF20				
Displays / operating elements						
Display	Switching status	LED, yellow I1...I4				
	Power	LED, green AS-i, AUX				
	errors	LED, red				
Accessories						
Accessories (optional)		connector				
Remarks						
Pack quantity		1 pcs.				



AS-Interface control cabinet module

SmartL25 4DI C

Electrical connection

pin header:

Connection

I-	I-	E+	E-
I1	I2	I3	I4
I+	I+	I+	I+

A+	A-		

A+	AS-i +
A-	AS-i -
I+	Sensor supply +24V
I-	Sensor supply 0V
E+	External sensor supply +24V
E-	External sensor supply 0V
I1...I4	Switching input sensor 1...4