

AC2307




AS-Interface dual sensor for pneumatic quarter-turn actuators

DUAL SENSOR T6 2SI 2DO T M12

Article no longer available - archive entry

Alternative articles: AC2317

When selecting an alternative article and accessories please note that technical data may differ!

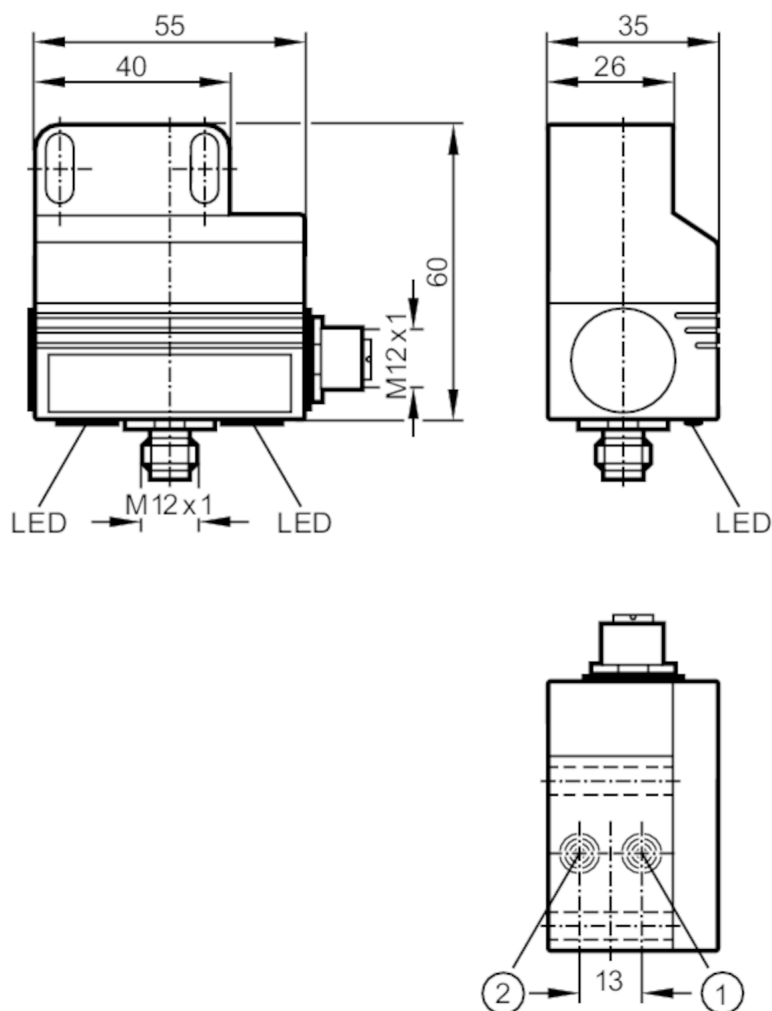

- 1 sensor 1
- 2 sensor 2



Product characteristics

Sensing range	[mm]	4
Dimensions	[mm]	55 x 60 x 35

Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Monitoring range

Sensing range	[mm]	4
---------------	------	---


Operating conditions

Ambient temperature	[°C]	-20...70
Protection		IP 67



AS-Interface dual sensor for pneumatic quarter-turn actuators

DUAL SENSOR T6 2SI 2DO T M12

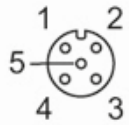Tests / approvals		
EMC	EN 50081-1	
	EN 61000-6-2	
AS-i classification		
AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	F
AS-i certificate		15101
Mechanical data		
Mounting		non-flush mountable
Dimensions	[mm]	55 x 60 x 35
Material		PBT; PC
Displays / operating elements		
Display	Power	1 x LED, green
	Function	1 x LED, red
Remarks		
Pack quantity		1 pcs.
Electrical connection - Socket		
Connector: 1 x M12; coding: A; Moulded body: stainless steel		
		
Connection		
Ausgänge		
2	Switching output 2 +	
3	External voltage -	
4	Switching output 1 +	
Electrical connection - plug		
Connector: 1 x M12; coding: A; Moulded body: stainless steel		
		
Elektrischer Anschluss		
1	AS-i+	
3	AS-i -	