


AC2351



AS-Interface illuminated pushbutton module

Push-button modul 8I/8O

Article no longer available - archive entry

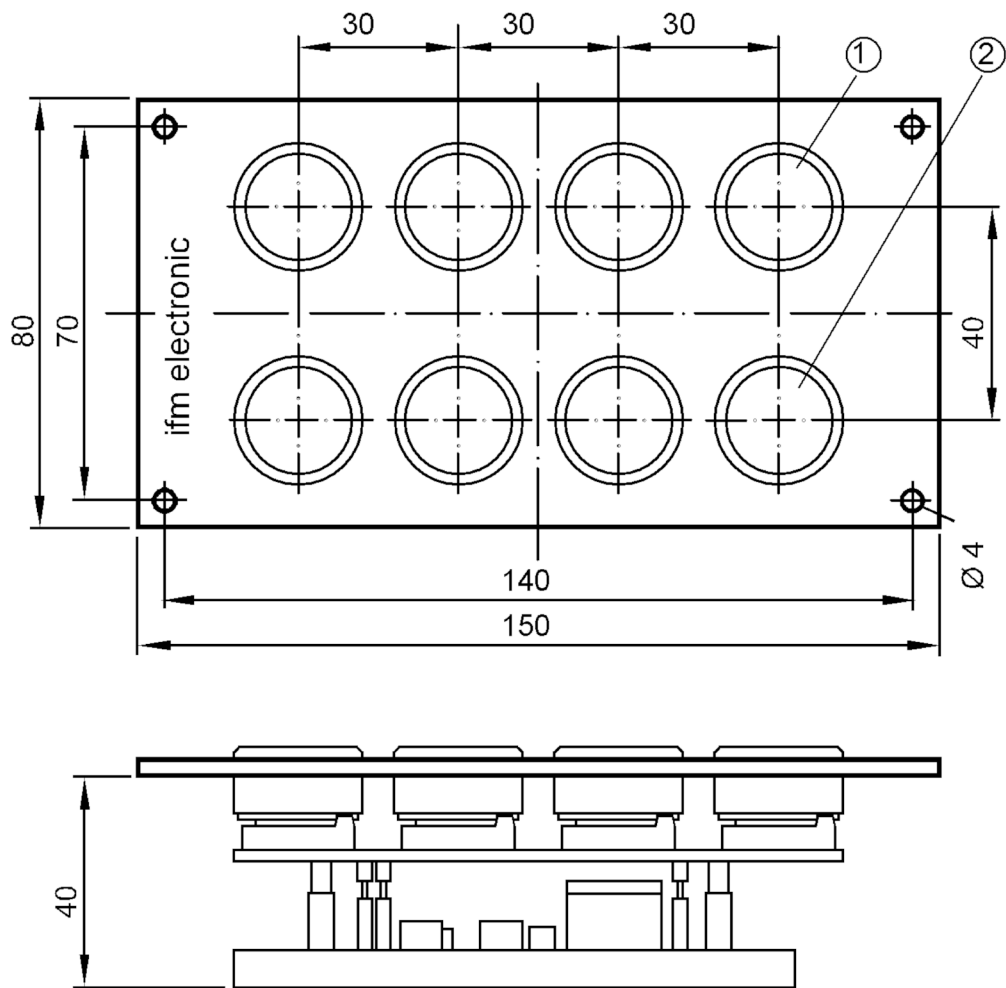

- 1 green
- 2 red



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 150
Reverse polarity protection		yes
Outputs		
Electrical design		AS-i
Operating conditions		
Ambient temperature	[°C]	0...60
Protection		IP 00
Tests / approvals		
EMC	EN 50295	
AS-i classification		
AS-i profile		S-7.F

AC2351



AS-Interface illuminated pushbutton module

Push-button modul 8I/8O

AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	F
AS-i certificate		14401

Mechanical data

Material	front panel: aluminum
----------	-----------------------

Accessories

Accessories (optional)	Cover removal tool:, E70206
------------------------	-----------------------------

Remarks

Remarks	The pushbuttons (EAO type 84) provide protection against accidental contact. Housing and pushbuttons can be labeled.
Pack quantity	1 pcs.

Electrical connection

COMBICON:
