

AC315A




AS-Interface dual sensor for pneumatic quarter-turn actuators

DUAL SENSOR T4 2SI 3D

Article no longer available - archive entry

Alternative articles: AC336A
When selecting an alternative article and accessories please note that technical data may differ!

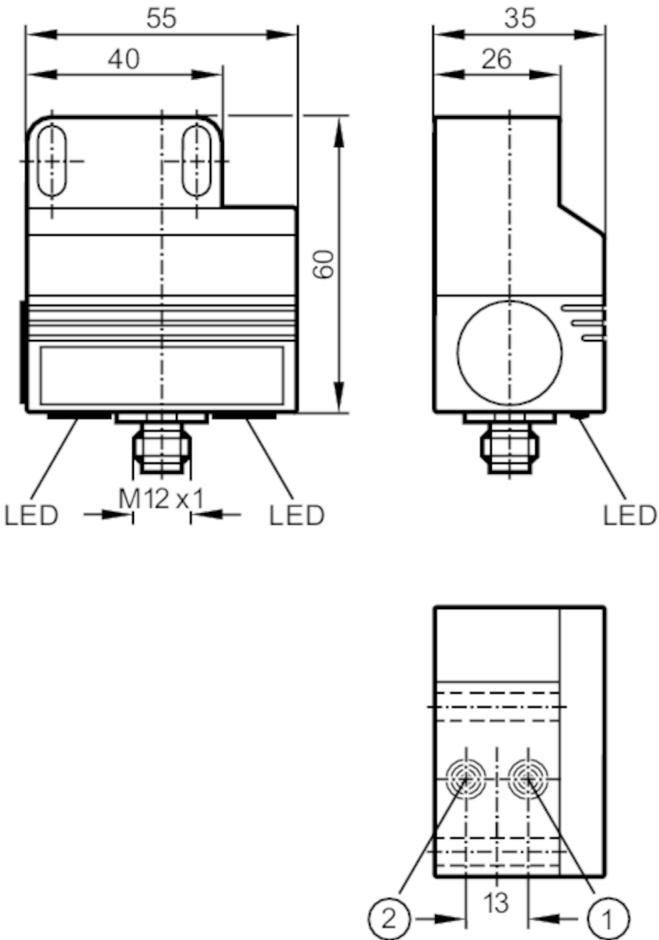

- 1 sensor 1
- 2 sensor 2



Product characteristics		
Sensing range	[mm]	4
Dimensions	[mm]	55 x 60 x 35
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 40
Protection class		III
Monitoring range		
Sensing range	[mm]	4
Operating conditions		
Ambient temperature	[°C]	-10...60
Protection		IP 5x; (when used outside the hazardous area: IP 67)

AC315A



AS-Interface dual sensor for pneumatic quarter-turn actuators

DUAL SENSOR T4 2SI 3D

Tests / approvals

ATEX marking	 II 3D Ex tD A22 IP5X T80°C X Ta: -10...60°C
Note on ATEX marking	only in conjunction with the mounting plate
EMC	EN 50295

AS-i classification

AS-i version	2.1
Extended addressing mode	yes
AS-i I/O configuration [hex]	0
AS-i ID code [hex]	A.F
AS-i certificate	74901

Mechanical data

Weight [g]	163.8
Mounting	non-flush mountable
Dimensions [mm]	55 x 60 x 35
Material	PBT

Displays / operating elements

Display	Switching status	2 x LED, yellow
---------	------------------	-----------------

Accessories


Items supplied	Mounting plate: 1 socket head screws: 2 x M5 x 35
----------------	--

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12; coding: A; Locking: stainless steel (1.4305 / 303)

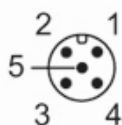

Connection

