


# AC5011



## Lower part for AS-Interface module

EEMS-Base FC Addressing socket

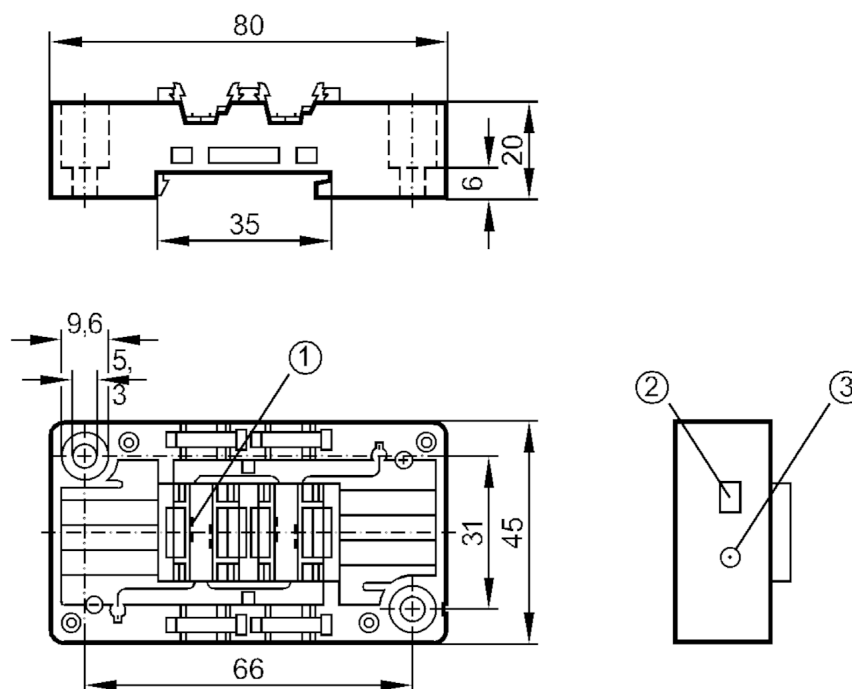

- 1 contact pins
- 2 panel for labelling
- 3 Addressing socket



### Electrical data

Operating voltage	[V]	26.5...31.6 DC
Additional voltage supply	[V]	24 DC

### Outputs

Electrical design	AS-i
Contact rating	< 2 A

### Operating conditions

Ambient temperature	[°C]	-25...85
Protection	IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)	

### AS-i classification

AS-i addressing	Addressing socket
-----------------	-------------------

### Mechanical data

Weight	[g]	61
Type of mounting	Mounting on DIN rail and panel	
Dimensions	[mm]	45 x 80 x 20
Material	PBT	

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

contact pins in module upper part :  
quick mounting technology for AS-i flat cable: