

AC5013




Lower part for AS-Interface module

EEMS-Base FC Addr.-socket V2A

Article no longer available - archive entry

Alternative articles: AC5015

When selecting an alternative article and accessories please note that technical data may differ!

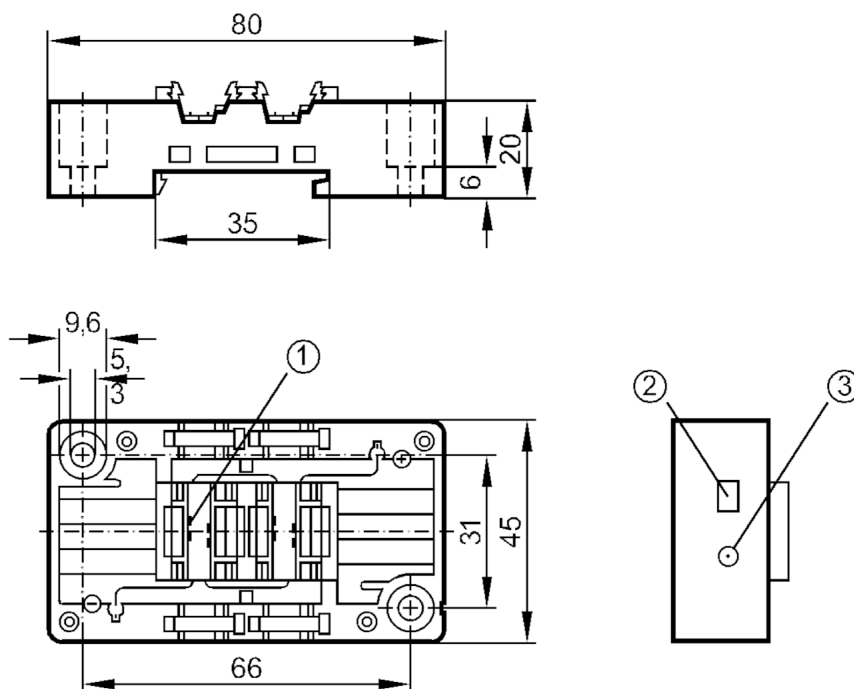

- 1 contact pins
- 2 panel for labelling
- 3 Addressing socket



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Additional voltage supply	[V]	24 DC

Outputs

Electrical design	AS-i
Contact rating	< 2 A

Operating conditions

Ambient temperature	[°C]	-25...85
Protection	IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)	

AS-i classification

AS-i addressing	Addressing socket
-----------------	-------------------

Mechanical data

Type of mounting	Mounting on DIN rail and panel	
Dimensions	[mm]	45 x 80 x 20
Material	PBT; stainless steel (1.4305 / 303)	

Remarks

Pack quantity	1 pcs.
---------------	--------

AC5013



Lower part for AS-Interface module

EEMS-Base FC Addr.-socket V2A

Electrical connection

contact pins in module upper part :

quick mounting technology for AS-i flat cable: