


AC5031



Lower part for AS-Interface module

EMS-BASE RC ST SET

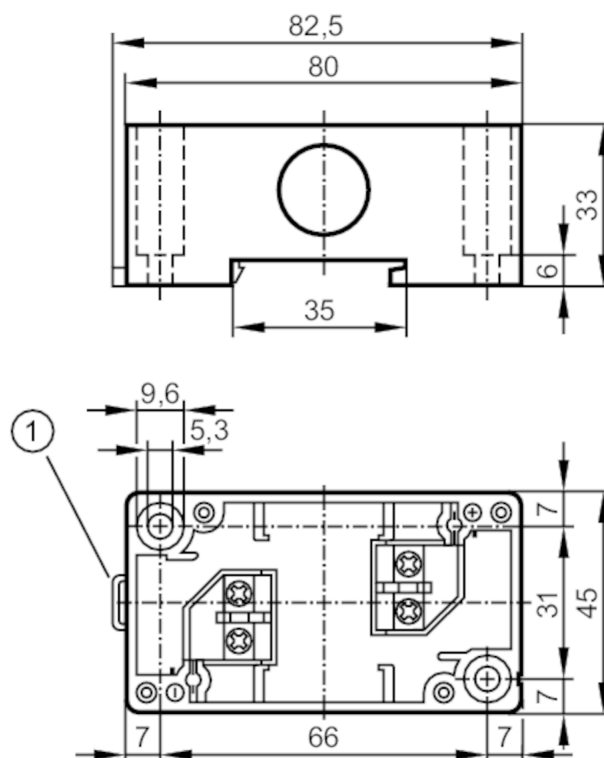

1 locking bolt

Electrical data

Operating voltage [V] 26.5...31.6 DC

Outputs

Electrical design AS-i

Contact rating < 4 A

Operating conditions

Ambient temperature [°C] -25...85

Protection IP 65

Mechanical data

Weight [g] 115.2

Type of mounting Mounting on DIN rail and panel

Material PBT

Accessories

Items supplied flat cable seals: 2, NBR

cable glands: 3

Protective caps: 3

Hexagon nuts: 4

Accessories (optional) cover:, for AS-i module, AC3000

screw terminal insert:, AC5007

Remarks

Remarks up to 4 M20 cable ports for any T and cross branches

Pack quantity 1 pcs.

AC5031



Lower part for AS-Interface module

EMS-BASE RC ST SET

Electrical connection

screw terminals: ...2.5 mm²