


AC9240



AS-Interface module

MODULE ASI PG7/9 4E 200M

Article no longer available - archive entry

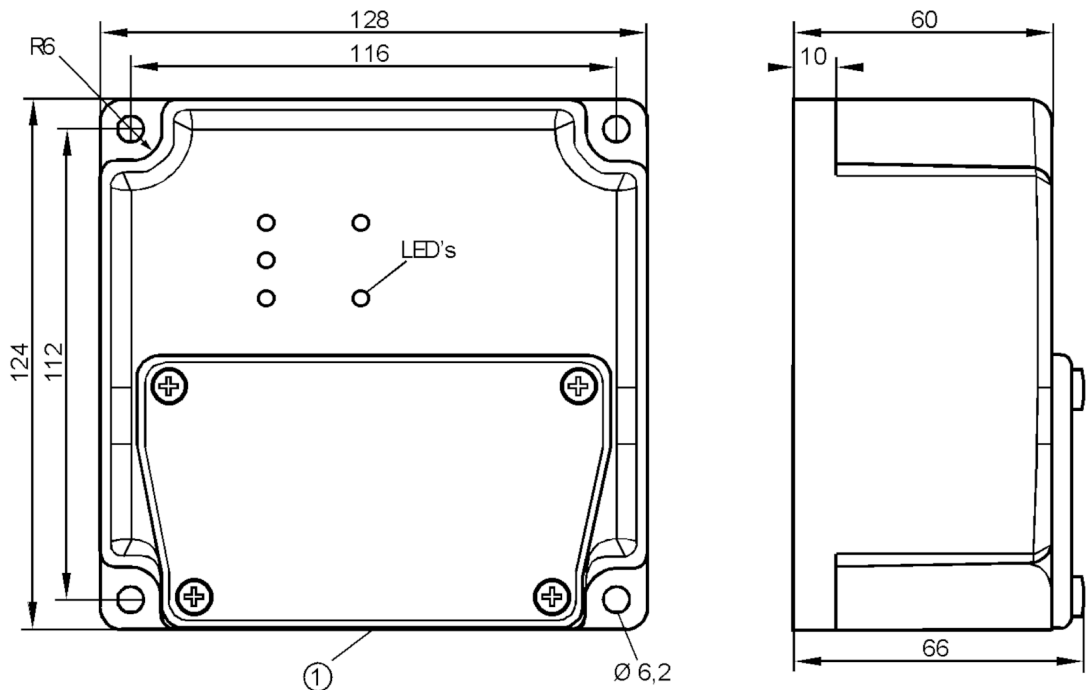

1 6 Outputs with PG cable gland



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 240
Reverse polarity protection		yes
Integrated watchdog		yes

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

Inputs

Number of digital inputs		4
Sensor supply of the inputs		AS-i / AUX
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	> 5
Input current low	[mA]	< 1.5
Switching level high	[V]	> 10
Digital inputs protected against short circuits		yes

Outputs

Electrical design	AS-i
Circuit	PNP

AC9240



AS-Interface module

MODULE ASI PG7/9 4E 200M

Short-circuit proof		yes
Electrically separated		yes
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 68
Tests / approvals		
EMC	EN 50081-1	
	EN 61000-6-2	
AS-i classification		
AS-i profile		S-0.0
AS-i I/O configuration	[hex]	0
AS-i ID code	[hex]	0
Mechanical data		
Material		PA
Displays / operating elements		
Display	Switching status	LED, yellow
	Power	LED, green
Accessories		
Accessories (optional)	PG cable gland: 2 x PG9	
	PG cable gland: 4 x PG7	
Remarks		
Pack quantity		1 pcs.