


CR0403



Programmable controller for mobile machines

R360/BasicController 12/12

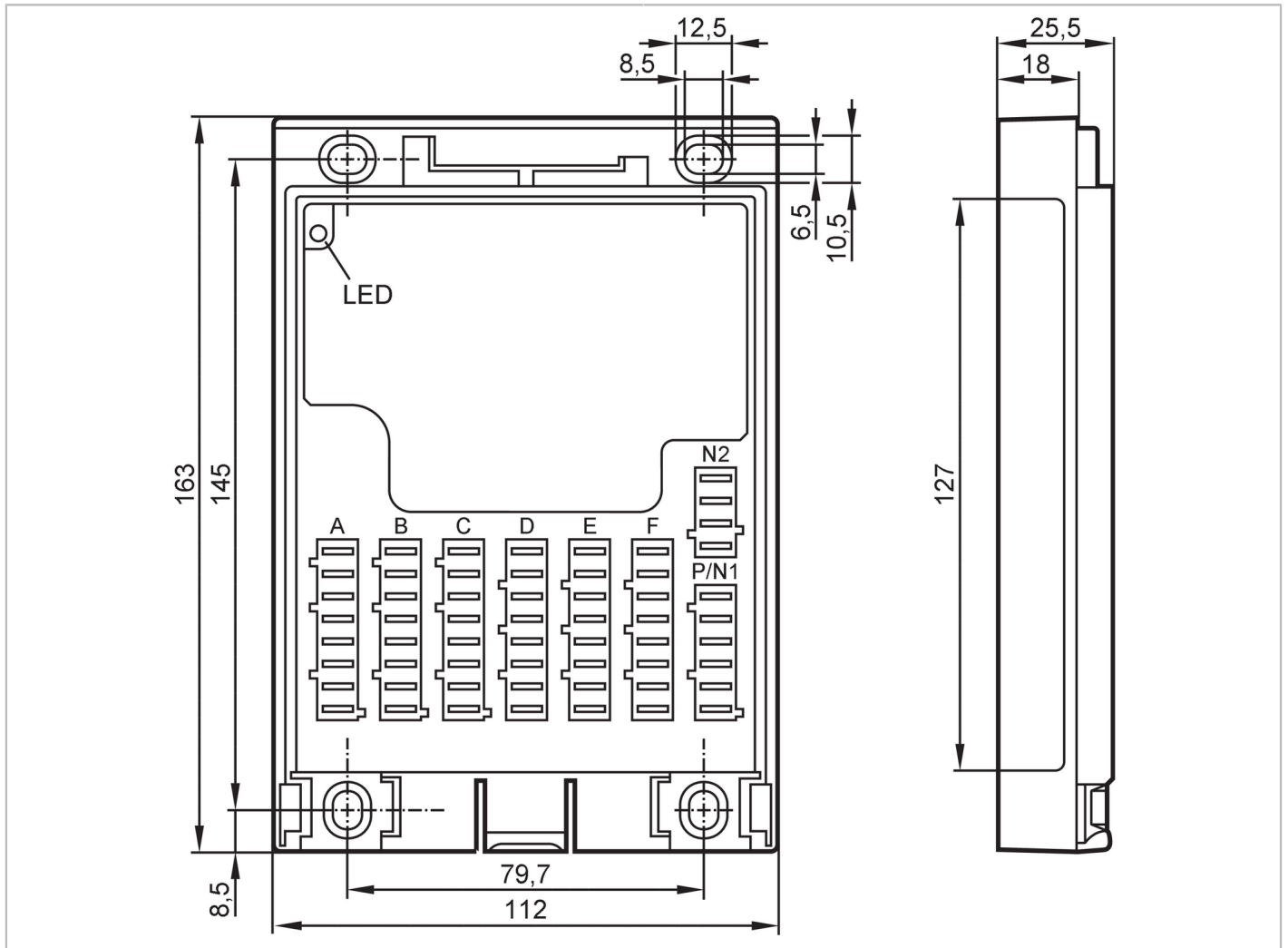

Electrical data	
Operating voltage	[V] 8...32 DC
Inputs / outputs	
Total number of inputs and outputs	24
Number of inputs and outputs	Number of digital inputs: 12; Number of analog inputs: 4; Number of frequency inputs: 4; Number of resistor inputs: 4; Number of digital outputs: 12
Inputs	
Number of frequency inputs	4
Number of resistor inputs	4
Number of digital inputs	12
Number of analog inputs	4
Analog input (current)	[mA] 0...20
Analog input (voltage)	[V] 0...32
Outputs	
Number of digital outputs	12
Number of PWM outputs	10

CR0403



Programmable controller for mobile machines

R360/BasicController 12/12

Number of PWM-I outputs	2
Software / programming	
Parameter setting options	input/output functions
PLC function to IEC 61131-3	yes
Interfaces	
Number of CAN interfaces	2
Tests / approvals	
MTTF [years]	111
Mechanical data	
Weight [g]	404.95
Housing	rectangular
Type of mounting	Backplane mounting
Dimensions [mm]	163 x 112 x 25.5
Remarks	
Pack quantity	1 pcs.