


CR0451



Programmable graphic display for controlling mobile machines

R360/BasicDisplay

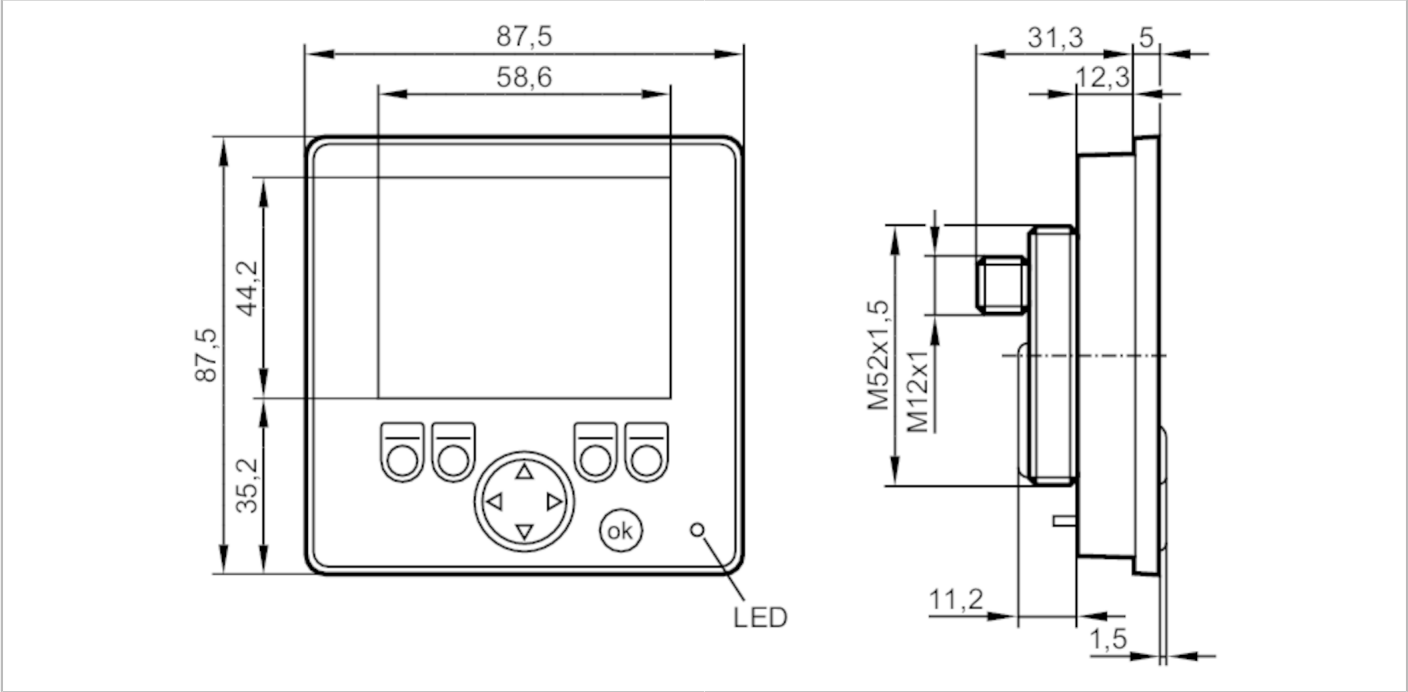

Electrical data		
Operating voltage	[V]	8...32 DC
Software / programming		
PLC function to IEC 61131-3		yes
Interfaces		
Number of CAN interfaces		1
Tests / approvals		
MTTF	[years]	232
Mechanical data		
Weight	[g]	165
Type of mounting		panel/surf.
Dimensions	[mm]	87.5 x 87.5 x 37.7
Displays / operating elements		
Display		2,8" Color display
Operating elements	5	freely programmable backlit function keys
	1	Navigation key for cursor function
Display resolution		320 x 240
Display type		Color display
Display size		2.8"
Display background illumination		LED
Remarks		
Pack quantity		1 pcs.

CR0451




Programmable graphic display for controlling mobile machines

R360/BasicDisplay

Electrical connection

Connector: 1 x M12; coding: A

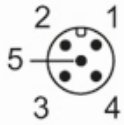

- 1 n.c.
- 2 8...32 V DC
- 3 GND
- 4 CAN_H
- 5 CAN_L