


CR0452



Programmable Human Machine Interface

R360/BasicDisplay XL

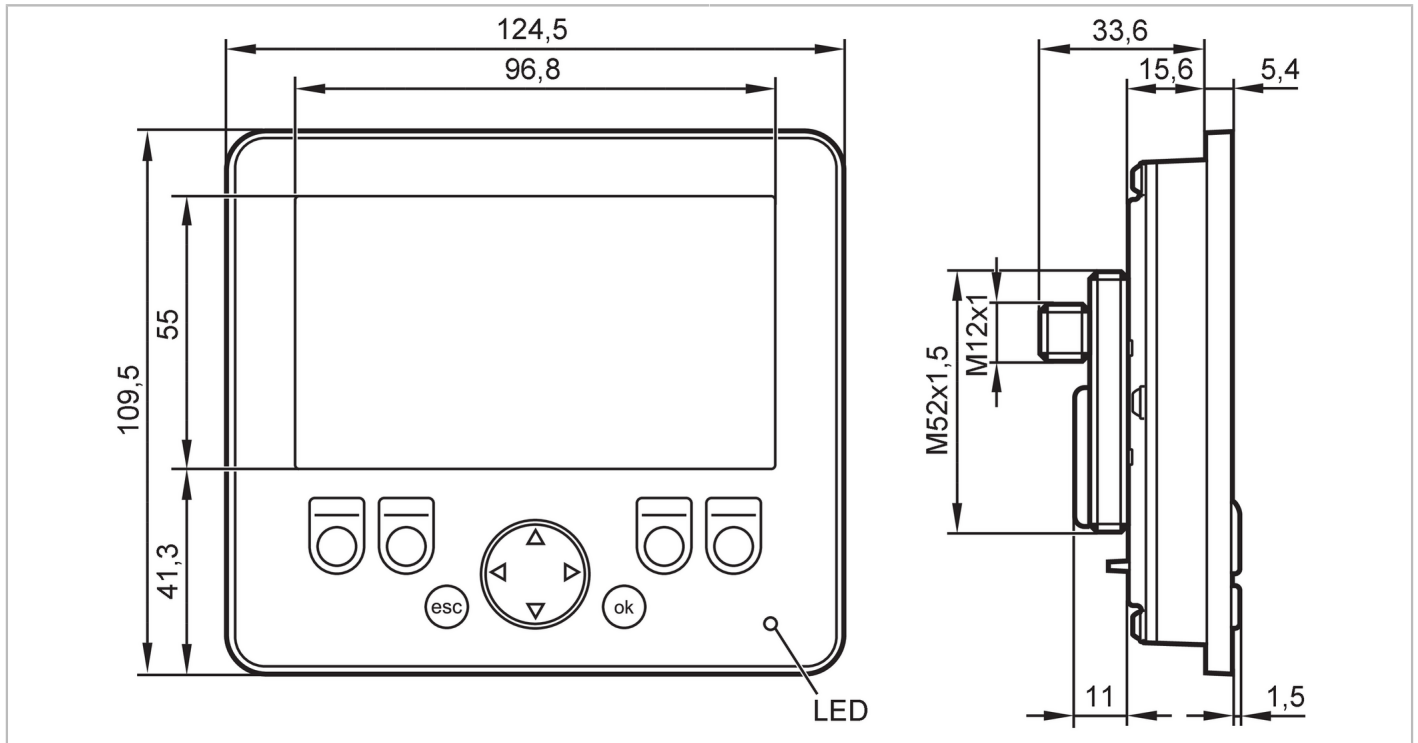

Product characteristics		
Operating elements	6	freely programmable backlit function keys
	1	Navigation key for cursor function
Display type		Color display
Electrical data		
Operating voltage	[V]	8...32 DC
Software / programming		
PLC function to IEC 61131-3		yes
Interfaces		
Number of CAN interfaces		1
Tests / approvals		
MTTF	[years]	237
Mechanical data		
Weight	[g]	291.5
Housing		rectangular
Type of mounting		panel/surf.
Dimensions	[mm]	109.5 x 124.5 x 40.5
Displays / operating elements		
Display		4,3" Color display
Operating elements	6	freely programmable backlit function keys
	1	Navigation key for cursor function
Display resolution		480 x 272
Display type		Color display

CR0452



Programmable Human Machine Interface

R360/BasicDisplay XL


Display size	4.3"
Display background illumination	LED

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

 Connector: 1 x M12; coding: A; Contacts: 5



- 1 n.c.
- 2 8...32 V DC
- 3 GND
- 4 CAN_H
- 5 CAN_L