


CR2016



I/O modules for mobile machines

R360/CabinetModule/32I/0

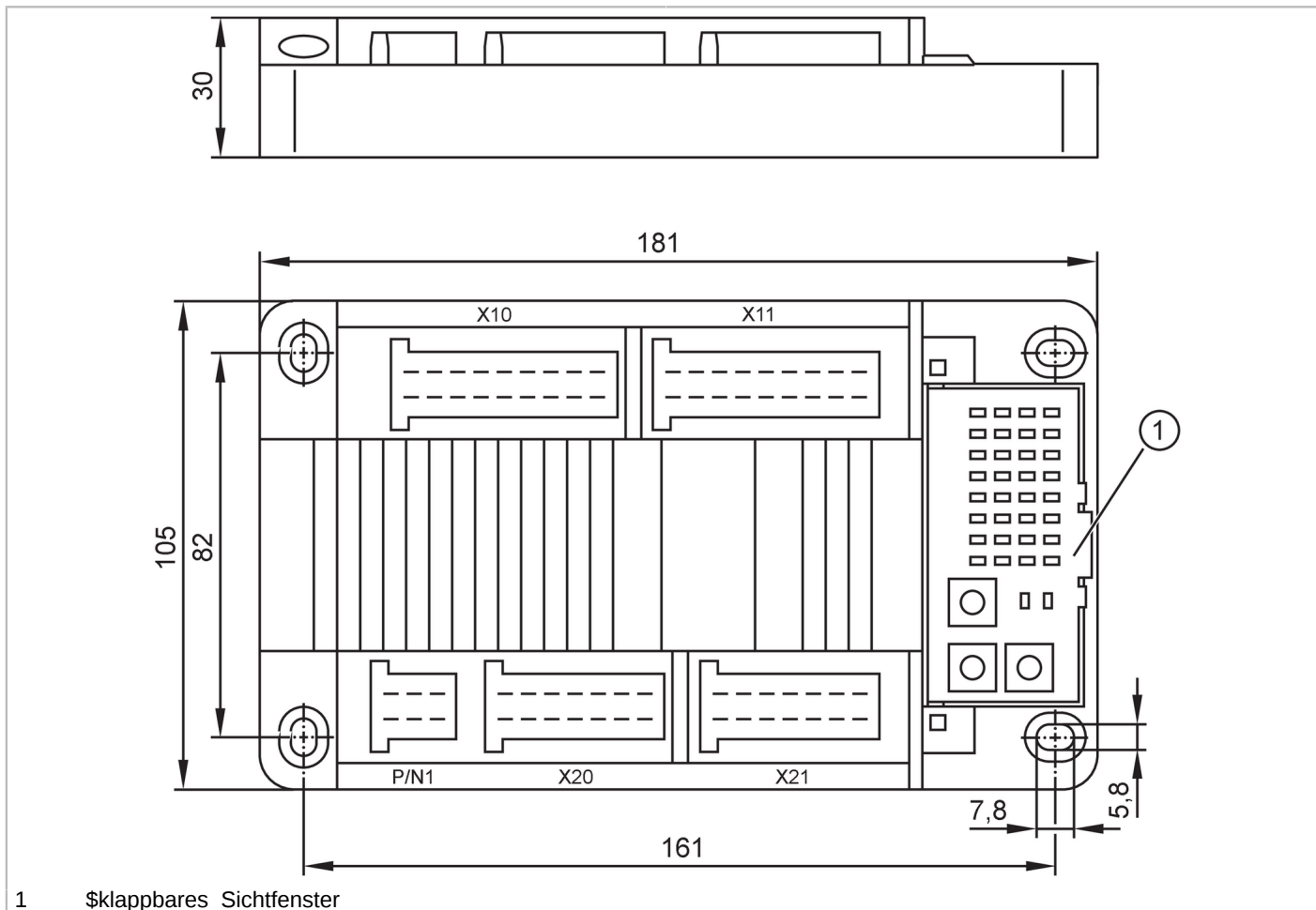

1 \$klappbares_Sichtfenster



Electrical data	
Operating voltage	[V] 10...32 DC
Inputs / outputs	
Total number of inputs and outputs	32
Number of inputs and outputs	Number of digital inputs: 16; Number of analog inputs: 4; Number of frequency inputs: 4; Number of digital outputs: 16
Inputs	
Number of frequency inputs	4
Number of digital inputs	16
Number of analog inputs	4
Analog input (current)	[mA] 0...20
Analog input (voltage)	[V] 0...32
Outputs	
Number of digital outputs	16
Number of PWM outputs	4
Software / programming	
Parameter setting options	input/output functions

CR2016



I/O modules for mobile machines

R360/CabinetModule/32I/0

Interfaces	
Number of CAN interfaces	1
Tests / approvals	
MTTF [years]	102
Mechanical data	
Weight [g]	501.2
Housing	rectangular
Type of mounting	Backplane mounting
Dimensions [mm]	181 x 105 x 30
Remarks	
Pack quantity	1 pcs.
Electrical connection	
AMP Crimp connector:	