


DF2212



Electronic circuit breaker

Fuse/IO-Link/24VDC/2x2A

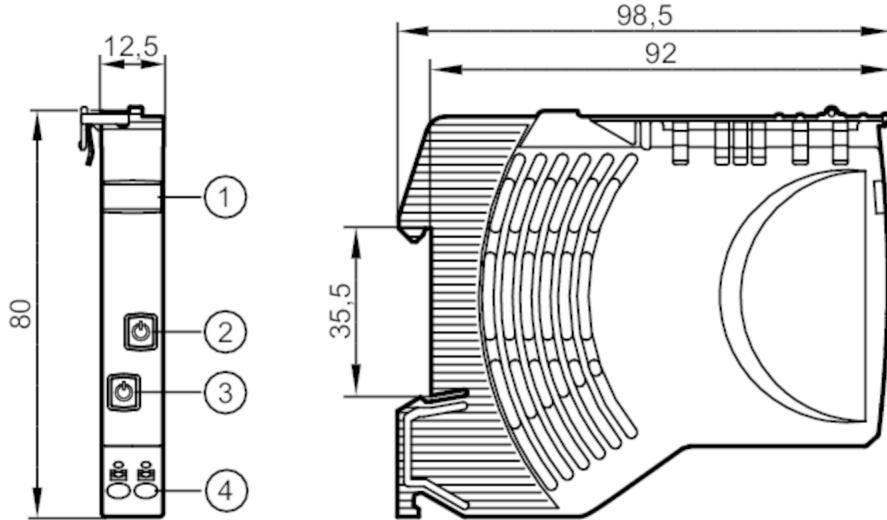

- 1 panel for labelling
- 2 pushbutton on / off / reset Status LED 2
- 3 pushbutton on / off / reset Status LED 1
- 4 push-in terminals Outputs 1/2



Electrical data

Operating voltage	[V]	to SELV/PELV ; "supply class 2" according to UR
Nominal voltage DC	[V]	24
Input voltage DC	[V]	19.2...30
Protection class		III
Mains buffering time (nominal voltage 24 V DC)		10
Closed-circuit current	[mA]	8
Number of channels		2
Nominal current	[A]	2
Nominal current (Fail Safe Element)	[A]	2

Outputs

Load capacitance, total	[mF]	10
-------------------------	------	----

Operating conditions

Ambient temperature	[°C]	-25...60
Storage temperature	[°C]	-40...70
Protection		IP 20; (on the front)
Degree of soiling		2

Tests / approvals

EMC	EN 61000-6-3	radiation of interference
	EN 61000-6-2	noise immunity

Mechanical data

Weight	[g]	72.5
--------	-----	------

DF2212



Electronic circuit breaker

Fuse/IO-Link/24VDC/2x2A

Dimensions

[mm]

80 x 12.5 x 98.5

Displays / operating elements

Display status 2 x LED, red / green / orange


Operating elements 2 x pushbuttons

Electrical connection

push-in terminals:


contact lever/strip:

Connection

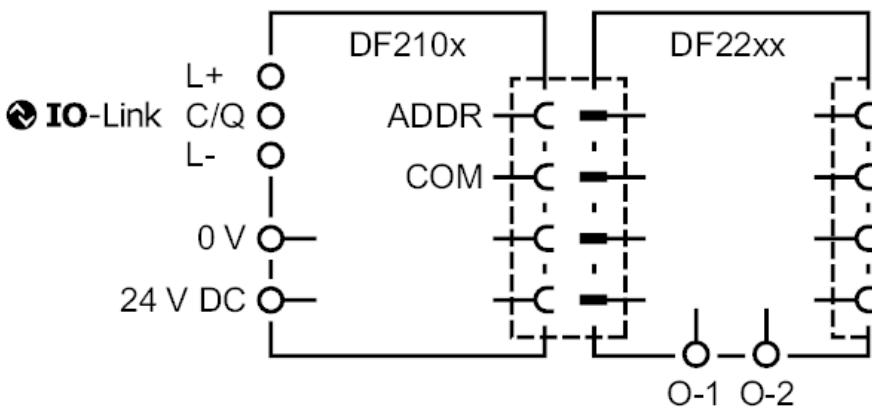

Diagrams and graphs

Output curve

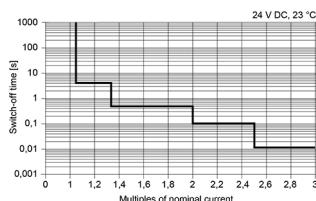

Time-current characteristics