

DN0512




Switching amplifier

N605/110VAC/0,8A

Article no longer available - archive entry

Alternative articles: DN1020

When selecting an alternative article and accessories please note that technical data may differ!

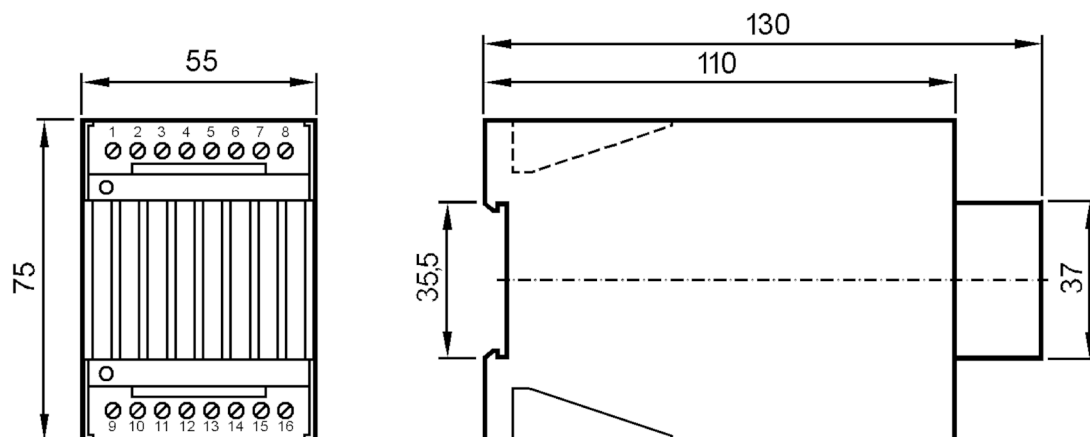

Electrical data

Nominal frequency AC	[Hz]	47...63
Output voltage	[V]	set
Output voltage tolerance	[%]	5
Max. output current at min. output voltage	[A]	0.8
Number of output circuits		1

Outputs

Short-circuit protection	yes
Overload protection	yes

Operating conditions

Ambient temperature	[°C]	0...50
Protection		IP 40

Mechanical data

Material	plastics
----------	----------

Displays / operating elements

Display	Output voltage	2 x LED, green
---------	----------------	----------------

Remarks

Pack quantity	1 pcs.
---------------	--------

DN0512



Switching amplifier

N605/110VAC/0,8A

Electrical connection

terminals: ...4 mm²

Connection

