

DN2001




Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/2,5A

Article no longer available - archive entry

Alternative articles: DN4011

When selecting an alternative article and accessories please note that technical data may differ!

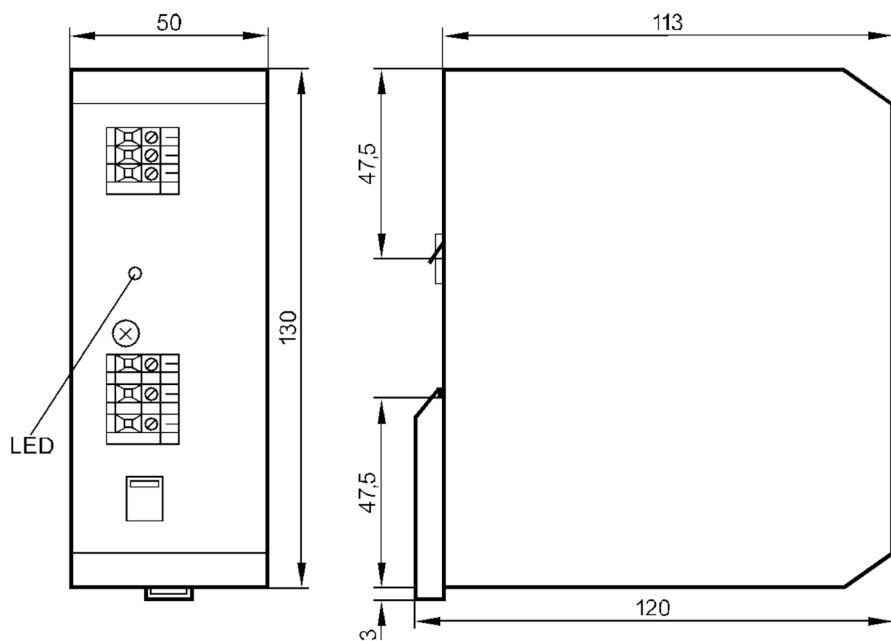

Electrical data

Nominal voltage AC	[V]	< 230; (selectable)
Nominal frequency AC	[Hz]	47...63
Input voltage range AC	[V]	88...132 / 187...264
Protection class		I
Max. power-on delay time	[ms]	42
Power-on delay time	[s]	42
Output voltage tolerance	[%]	2
Max. output current at min. output voltage	[A]	2.5
Number of output circuits		1
Max. residual ripple	[%]	1
Fuse	[A]	2; (built in)
Derating	[W/K]	1 (60...70 °C)

Outputs

Short-circuit protection	yes
Overload protection	yes

Operating conditions

Ambient temperature	[°C]	0...60
Protection		IP 20

DN2001



Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/2,5A

Tests / approvals

EMC	EN 60950/A2 1993	
	EN 50081-1	
	EN 61000-6-2	

Mechanical data

Material	aluminum
----------	----------

Displays / operating elements

Display	Function	LED, green
---------	----------	------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...2.5 mm²

Connection

