


DN2002



Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/5A

Article no longer available - archive entry

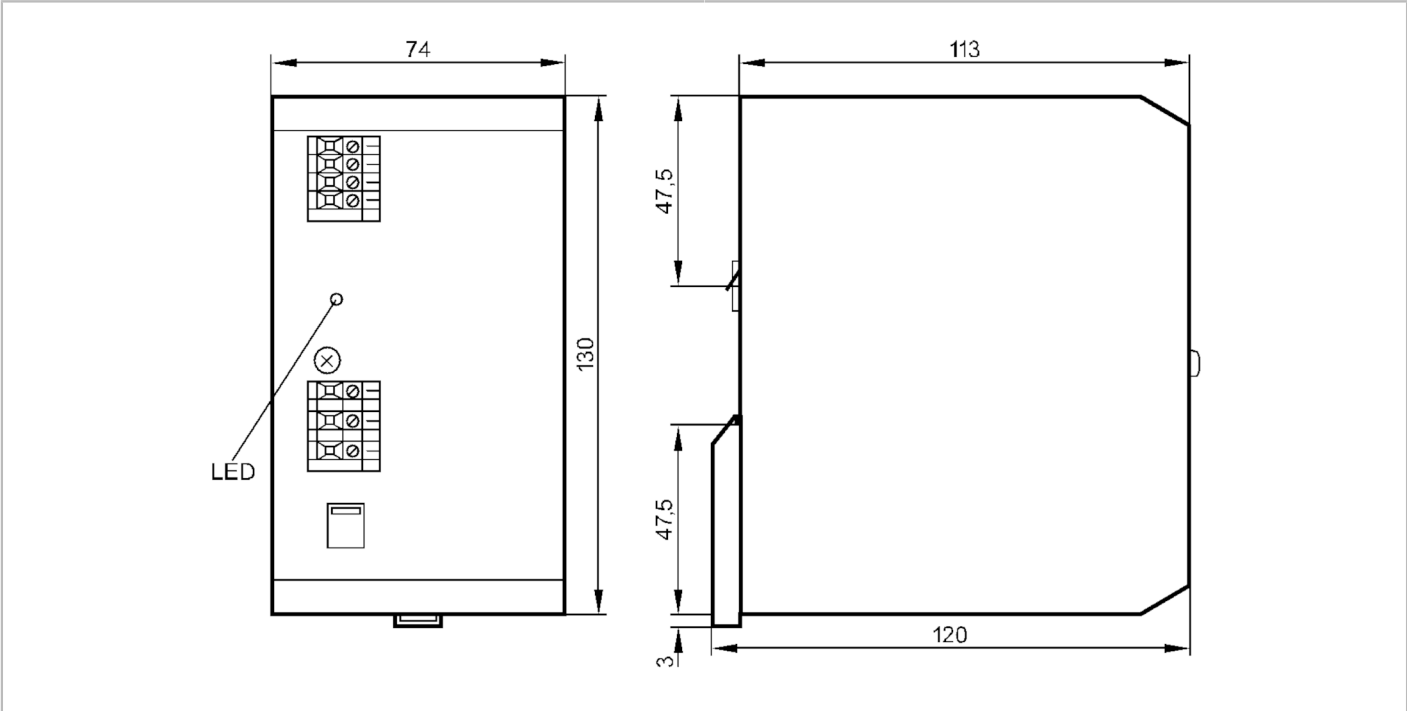

Electrical data		
Nominal voltage AC	[V]	< 230
Nominal frequency AC	[Hz]	47...63
Input voltage range AC	[V]	88...132 / 187...264
Protection class		I
Max. power-on delay time	[ms]	30
Power-on delay time	[s]	30
Output voltage tolerance	[%]	2
Max. output current at min. output voltage	[A]	5
Number of output circuits		1
Max. residual ripple	[%]	1
Fuse	[A]	2; (built in)
Derating	[W/K]	1 (60...70 °C)
Outputs		
Short-circuit protection		yes
Overload protection		yes
Operating conditions		
Ambient temperature	[°C]	0...60
Protection		IP 20

DN2002



Switched-mode power supply 24 V DC

POWER SUPPLY/24VDC/5A

Tests / approvals		
EMC	EN 60950/A2 1993	
	EN 50081-1	
	EN 61000-6-2	
Mechanical data		
Material	aluminum	
Displays / operating elements		
Display	Function	LED, green
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
terminals: ...2.5 mm²		
Connection		

