




Multifunction timer relay

T700/230VAC

Article no longer available - archive entry

Alternative articles: DL0201
When selecting an alternative article and accessories please note that technical data may differ!

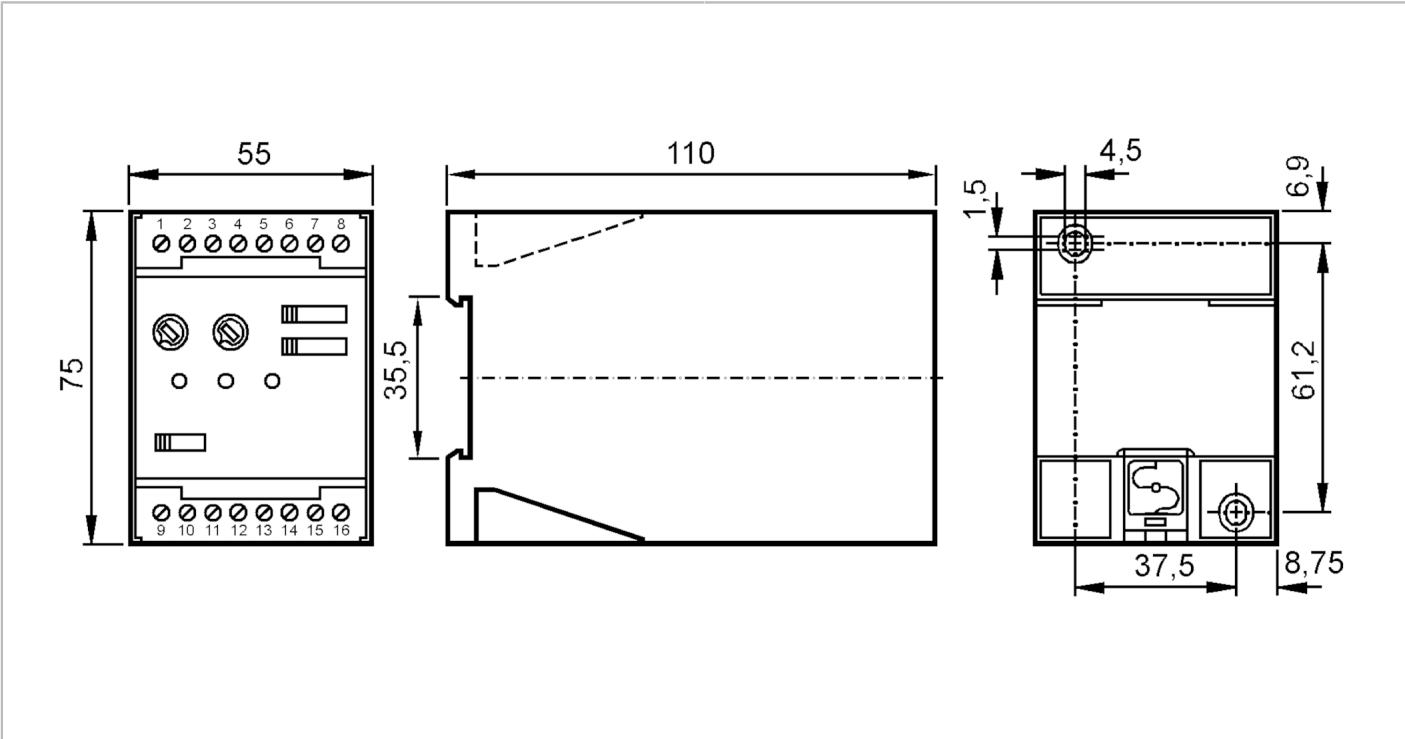

Product characteristics		
Housing	housing for DIN rail mounting	
Application		
Application	power supply and switching amplifier with timer function	
Electrical data		
Nominal voltage AC	[V]	< 230
Nominal voltage DC	[V]	24
Nominal voltage tolerance	[%]	10
Nominal voltage tolerance 2	[%]	10
Nominal frequency AC	[Hz]	50...60
Auxiliary energy for sensors DC	[V]	24; (±5 %, ≤ 40 mA)
Inputs / outputs		
Number of inputs and outputs	Number of relay outputs: 1	
Outputs		
Number of relay outputs	1	
Contact rating	8 A / 1250 VA / 250 V AC	
Accuracy / deviations		
Repeatability	[% of Sr]	< 3



Multifunction timer relay

T700/230VAC

Operating conditions		
Ambient temperature	[°C]	0...55
Protection		IP 40
Protection rating terminals		IP 20
Mechanical data		
Weight	[g]	444.4
Housing		housing for DIN rail mounting
Material		plastics
Displays / operating elements		
Display	Switching status	LED, green
	Power	1 x LED, green
Electrical connection		
terminals: ...4 mm²		
Connection		

