




Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/AC/DC

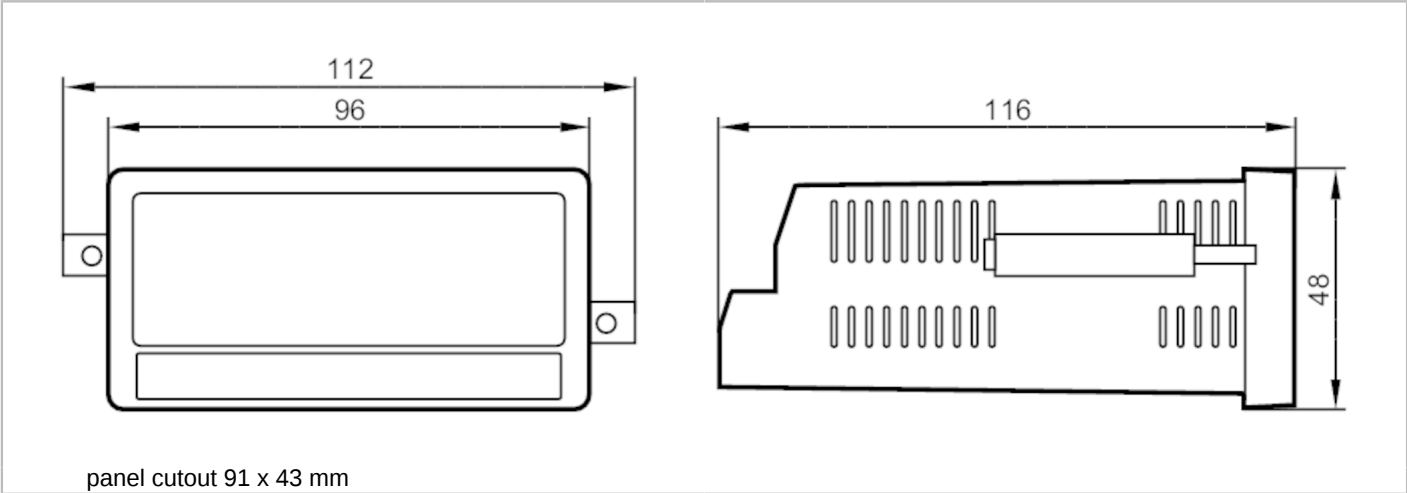

Product characteristics		
Dimensions	[mm]	48 x 112 x 116
Application		
Application	universal evaluation and display for all physical units which can be derived from pulse sequences	
Electrical data		
Frequency AC	[Hz]	50...60
Operating voltage	[V]	115...230 AC / 18...30 DC
Current consumption	[mA]	100
Inputs / outputs		
Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 4	
Inputs		
Number of digital inputs	2	
Outputs		
Number of digital outputs	4	
Overload protection	yes	
Operating conditions		
Ambient temperature	[°C]	-20...60
Storage temperature	[°C]	-25...70
Protection	IP 65	
Protection rating terminals	IP 20	
Tests / approvals		
EMC	EN 61000-6-2	
	EN 61000-6-3	
	EN 61000-6-4	
Mechanical data		
Weight	[g]	352
Type of mounting	panel cutout: 91 x 43 mm	
Dimensions	[mm]	48 x 112 x 116



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/AC/DC

Material	Noryl UL94-V-0
----------	----------------


Displays / operating elements

Display	Color display	full graphic LCD display, Touch screen
---------	---------------	--

Electrical connection

screw terminals:

Connection

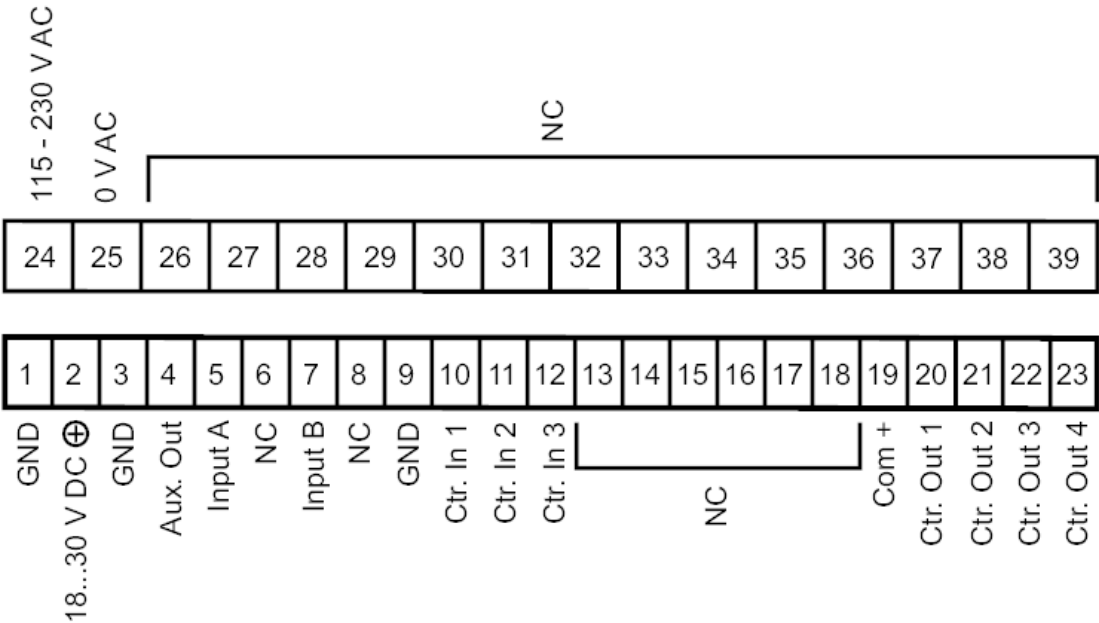

NC: not used