


E3M120



Connection cable

MCI CONNECTION CABLE 0.25M

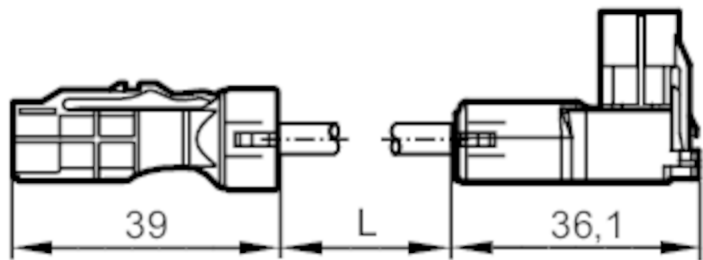

Application		
System	Drag chain suitability	
Electrical data		
Operating voltage	[V]	< 25 AC / < 60 DC
Operating conditions		
Ambient temperature	[°C]	-40...105
Protection	IP 67	
Mechanical data		
Weight	[g]	39.55
Drag chain suitability	yes	
Drag chain suitability	Bending radius for fixed installation	≥ 40 mm
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 0.25 m, TPU (urethane), black		