


E3M151



Connection cable

CONNECTION CABLE M12 5M

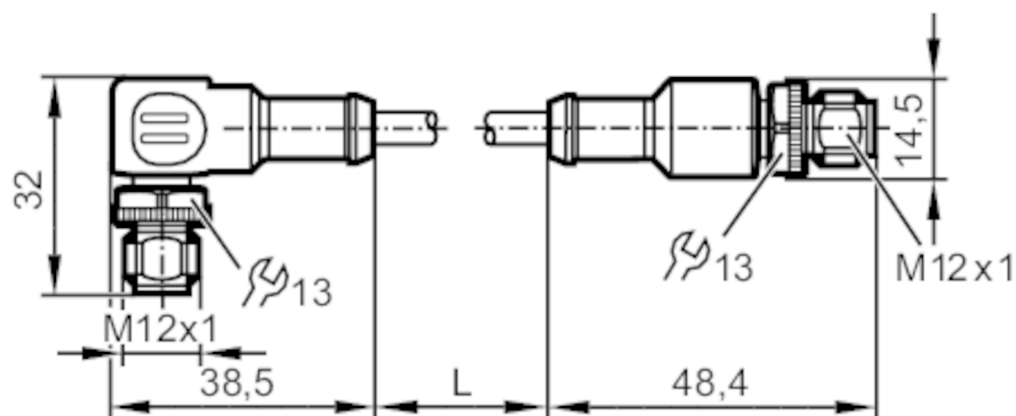

Application		
System		screened cable; Drag chain suitability
Design		for 3D Smart sensor mobile with analog video output PAL
Electrical data		
Operating voltage	[V]	< 25 AC / < 60 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-40...80
Protection		IP 67; IP 69K
Mechanical data		
Weight	[g]	274.3
Material		housing: PUR; sealing: FKM; contact pins: CuSn6 nickel-plated and tin-plated
Material nut		stainless steel (1.4305 / 303)
Drag chain suitability		yes
Drag chain suitability	Bending radius for fixed installation	≥ 60 mm
Remarks		
Pack quantity		1 pcs.

E3M151




Connection cable

CONNECTION CABLE M12 5M

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Locking: stainless steel (1.4305 / 303)

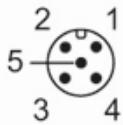

Electrical connection

Cable: 5 m, TPU (urethane), black, Ø 6 mm, screened; 3 x 0.25 mm²

Connection

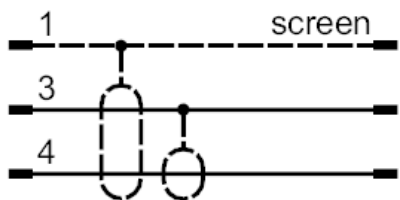

- 1: screen
- 2: not used
- 3: coax screen
- 4: coax cable core
- 5: not used

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Locking: stainless steel (1.4305 / 303)

