


E10407



Female cordset


ADOGF030MSS0010A03

Article no longer available - archive entry

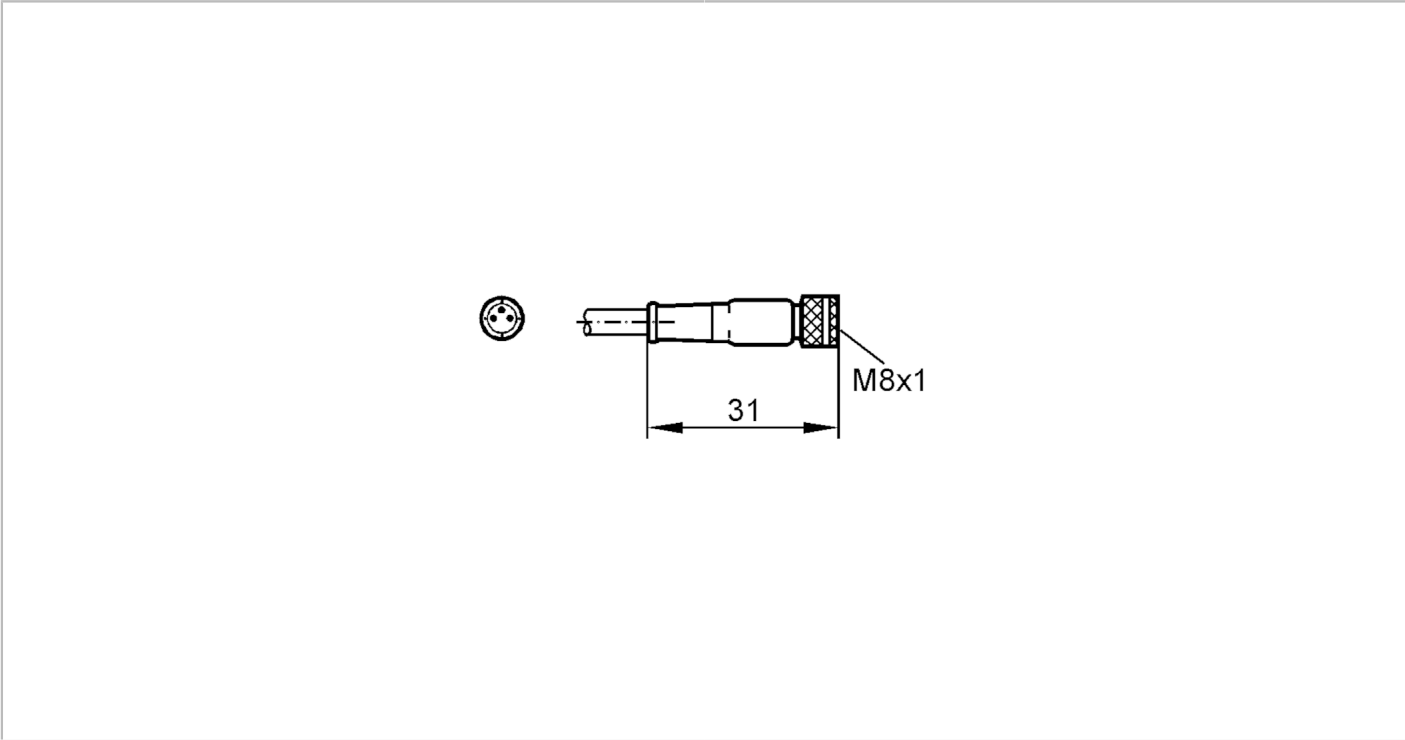

Electrical data		
Operating voltage	[M]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)		
Electrical connection - Socket		

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

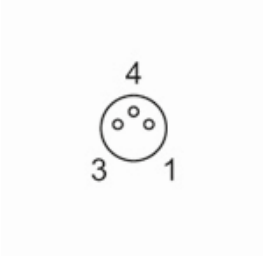


E10407



Female cordset

ADOGF030MSS0010A03

Connection

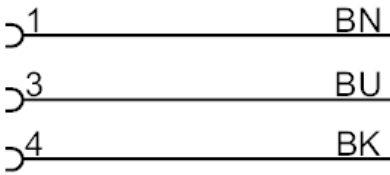

BN =	Core colors :	brown
BK =		black
BU =		blue