

E10408




Female cordset

ADOAH042MSS0002A03

Article no longer available - archive entry

Alternative articles: EVC007
When selecting an alternative article and accessories please note that technical data may differ!

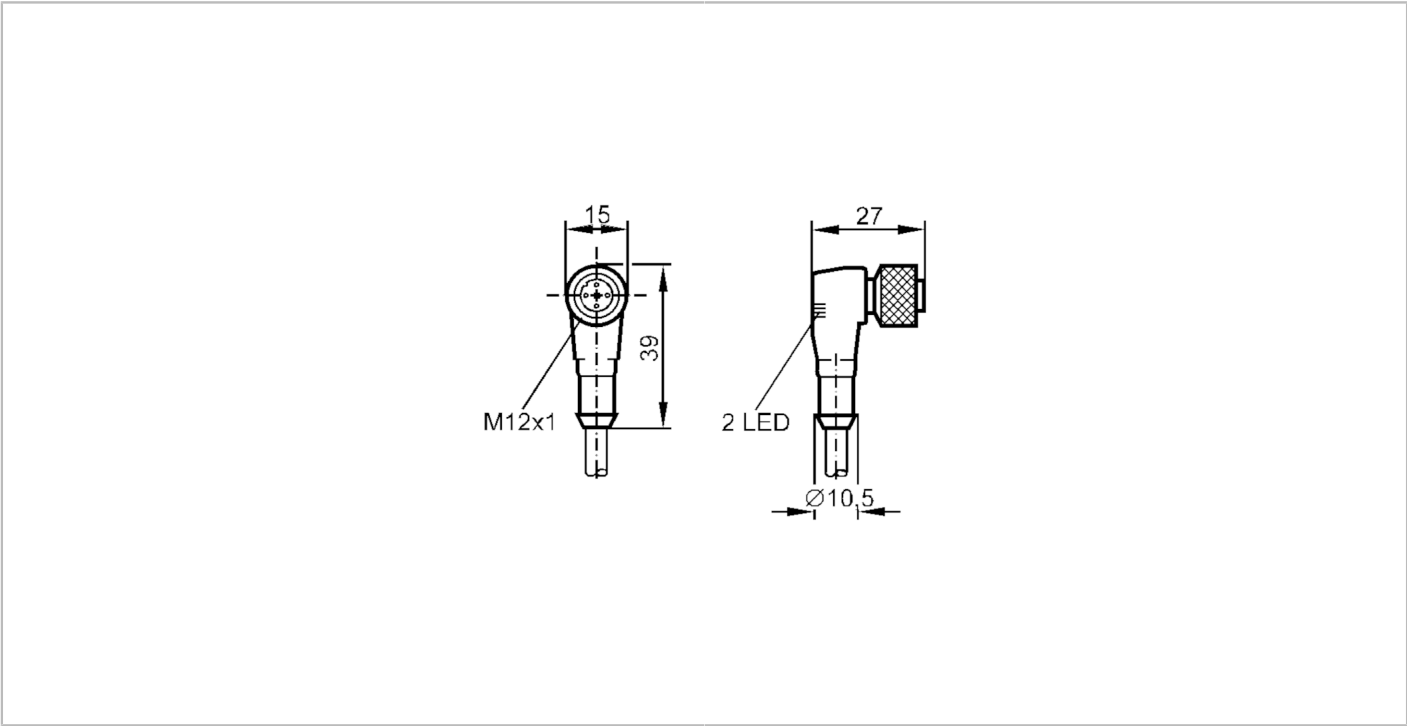

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10408



Female cordset

ADOAH042MSS0002A03

Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

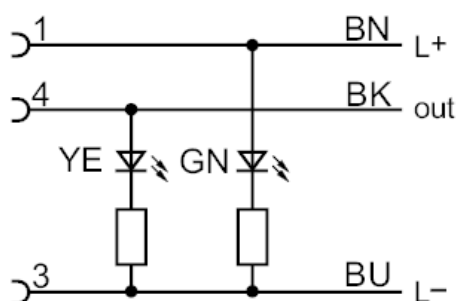

BN =	Core colors :
BK =	brown
BU =	black
	blue