


# E10411



## Male receptacle

ESTGH040MSS00,5E04 (PG9)

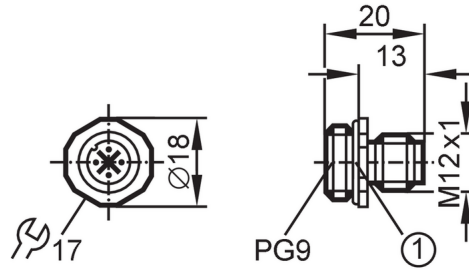

1 O-ring



### Application

Application Industrial applications

### Electrical data

Operating voltage [V]	< 250 AC/DC
Max. current load total [A]	4; (...40 °C)

### Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 67

### Mechanical data

Weight [g]	17.1
Dimensions [mm]	18 x 18 x 20
Mounting thread	PG 9
Material	housing: diecast zinc nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm<sup>2</sup>

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 4




# E10411



## Male receptacle

ESTGH040MSS00,5E04 (PG9)

### Connection

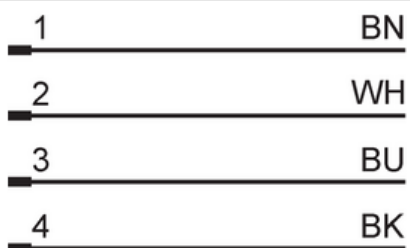

Core colors :  
BK = black  
BN = brown  
BU = blue  
WH = white