

E10422




Female cordset

ADOAH042MSS0002A04

Article no longer available - archive entry

Alternative articles: EVC007

When selecting an alternative article and accessories please note that technical data may differ!

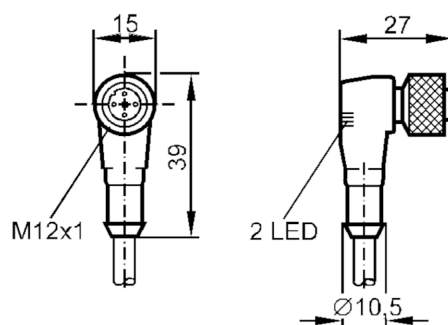

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane) transparent

Molded-body material TPU (urethane), transparent

Material nut brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10422



Female cordset

ADOAH042MSS0002A04

Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

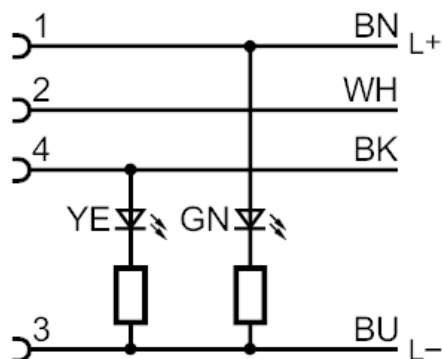

Core colors :
BN = brown
BK = black
BU = blue
WH = white